

ECOFAST Energy TT clamping connector for feeder 6 mm² 2 x Q4/2 socket

product category	Miscellaneous accessories
product designation	Power double-T terminal connector
product type designation	3RK1

General technical data	
degree of pollution	3
surge voltage resistance rated value	6 000 V
protection class IP	IP65
Substance Prohibitance (day/month/year)	05/01/2012
Net Weight	0.441 kg
operating voltage rated value maximum	690 V
operational current at AC at 400 V rated value	40 A

Ambient conditions	
ambient temperature during operation	-40 ... +125 °C

Installation/ mounting/ dimensions	
height	55 mm
width	107 mm
length	158 mm

Approvals Certificates		
Environment	General Product Approval	EMV

[Environmental Confirmations](#)



other

[Confirmation](#)



Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RK1911-2BG02>

Cax online generator


<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RK1911-2BG02>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/3RK1911-2BG02>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RK1911-2BG02&lang=en

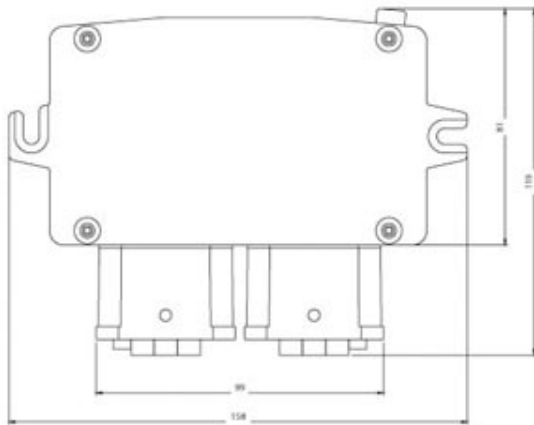

last modified:

4/18/2026 