


AS-i cable, shaped for external auxiliary voltage 24 V black, TPE, oil-resistant 2 x 1.5 mm², 100 m consists of 100 m cable

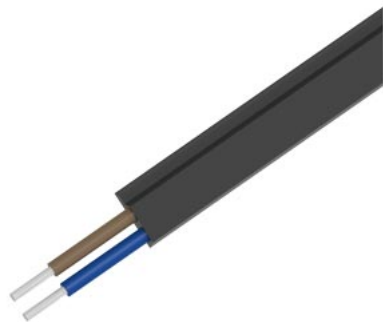

General technical data		
design of the product	AS-Interface shaped cables	
operating voltage rated value	300 V	
Mechanical data		
bending radius		
• for permanently laid cable minimum permissible	12 mm	
• with moving cable minimum permissible	24 mm	
Certificates/ approvals		
General Product Approval	other	Environment



[Confirmation](#)



[Environmental Conformations](#)

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875
Information for data generation and storage https://support.industry.siemens.com/cs/ww/en/view/109995012
Information- and Downloadcenter (Catalogs, Brochures,...) https://www.siemens.com/ic10
Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RX9023-0AA00
Cax online generator https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RX9023-0AA00
Service&Support (Manuals, Certificates, Characteristics, FAQs,...) https://support.industry.siemens.com/cs/ww/en/ps/3RX9023-0AA00
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...) https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RX9023-0AA00&lang=en

last modified: 11/19/2025