


AS-i cable, shaped for external auxiliary voltage 24 V black, pure, oil-resistant 2 x 1.5 mm², 1 km, on drum consists of 1000 m cable Shipbuilding approval

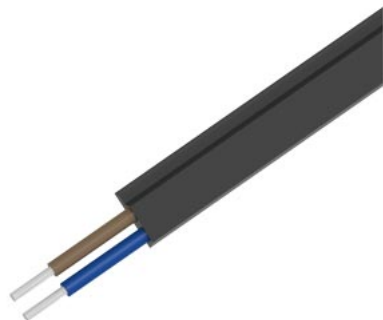

General technical data		
design of the product		AS-Interface shaped cables
operating voltage rated value		
300 V		
Mechanical data		
bending radius		
• for permanently laid cable minimum permissible		
• with moving cable minimum permissible		
		12 mm
		24 mm
Certificates/ approvals		
General Product Approval	other	Environment



[Confirmation](#)



[Environmental Con-
firmations](#)

Further information
Information on the packaging https://support.industry.siemens.com/cs/ww/en/view/109813875
Information for data generation and storage https://support.industry.siemens.com/cs/ww/en/view/109995012
Information- and Downloadcenter (Catalogs, Brochures,...) https://www.siemens.com/ic10
Industry Mall (Online ordering system) https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RX9026-0AA00
Cax online generator https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RX9026-0AA00
Service&Support (Manuals, Certificates, Characteristics, FAQs,...) https://support.industry.siemens.com/cs/ww/en/ps/3RX9026-0AA00
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...) https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RX9026-0AA00&lang=en

last modified: 11/19/2025