



incandescent lamp, 24 V AC/DC, 5 CO contacts, base BA15d, accessory for signaling columns, with diameter 50 mm + 70 mm, (packing unit 10 units)

product brand name	SIRIUS
product designation	Incandescent lamp
General technical data	
type of voltage of the operating voltage	AC/DC
operating voltage	
• 1 at DC rated value	24 V
• 1 at AC at 50 Hz rated value	24 V
• 1 at AC at 60 Hz rated value	24 V
relative positive tolerance of the operating voltage	10 %
relative negative tolerance of the operating voltage	-10 %
reference code according to EN 61346-2	P
Lamp	
type of light source	filament lamp
socket design	BA 15d
Enclosure	
height	42 mm
width	16 mm
outer diameter of the signal column element	70 mm
Ambient conditions	
ambient temperature during operation	-20 ... +50 °C
Approvals Certificates	
General Product Approval	Maritime application other



[Confirmation](#)



EG-Konf.



[Confirmation](#)

other

Environment

[Confirmation](#)



[Environmental Confirmations](#)



Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8WD4328-1XX>

Cax online generator

<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=8WD4328-1XX>


Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8WD4328-1XX>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=8WD4328-1XX&lang=en

-P

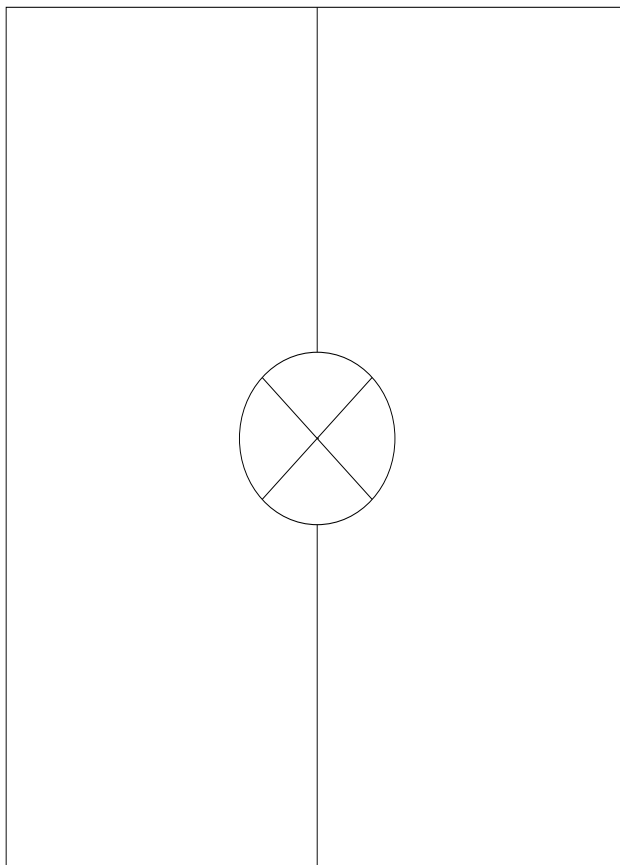

last modified:

4/1/2025 