

LED, base BA15d, yellow, 24 V AC/DC, accessory for signaling columns, with diameter 50 mm and 70 mm



Figure similar

product brand name	SIRIUS	
product designation	LED	
General technical data		
type of voltage of the operating voltage	AC/DC	
operating voltage		
• 1 at DC rated value		
• 1 at AC at 50 Hz rated value		
• 1 at AC at 60 Hz rated value		
relative positive tolerance of the operating voltage	10 %	
relative negative tolerance of the operating voltage	-15 %	
consumed current maximum	16 mA	
reference code according to EN 61346-2	P	
Lamp		
type of light source	LED	
light intensity	0.4 cd	
socket design	BA 15d	
Enclosure		
height	45 mm	
width	20 mm	
outer diameter of the signal column element	70 mm	
color	yellow	
Ambient conditions		
ambient temperature during operation	-20 ... +60 °C	
Approvals Certificates		
General Product Approval		other



[Confirmation](#)



EG-Konf.



[Confirmation](#)

[Confirmation](#)

other	Environment
-------	-------------



[Environmental Con-
firmations](#)



Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8WD4428-6XD>

Cax online generator

<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=8WD4428-6XD>


Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8WD4428-6XD>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=8WD4428-6XD&lang=en

-P

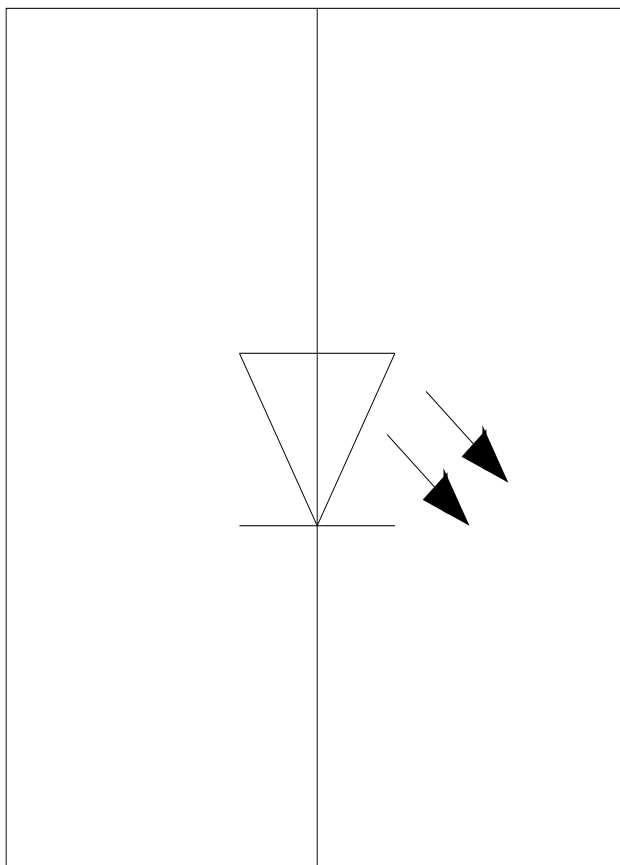

last modified:

4/1/2025 