

LED, base BA15d, red, 115 V AC, accessory for signaling columns, with diameter 50 mm and 70 mm



Figure similar

product brand name	SIRIUS
product designation	LED
General technical data	
type of voltage of the operating voltage	AC
operating voltage	
• 1 at AC at 50 Hz rated value	115 V
• 1 at AC at 60 Hz rated value	115 V
relative positive tolerance of the operating voltage	10 %
relative negative tolerance of the operating voltage	-15 %
reference code according to EN 61346-2	P
Lamp	
type of light source	LED
light intensity	2.88 cd
socket design	BA 15d
Enclosure	
height	45 mm
width	20 mm
outer diameter of the signal column element	70 mm
color	red
Ambient conditions	
ambient temperature during operation	-20 ... +60 °C
Approvals Certificates	
General Product Approval	other



[Confirmation](#)



EG-Konf.



[Confirmation](#)

[Confirmation](#)

other

Environment



[Environmental Confirmations](#)



Siemens EcoTech



Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8WD4448-6XB>

Cax online generator

<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=8WD4448-6XB>


Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8WD4448-6XB>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=8WD4448-6XB&lang=en

-P

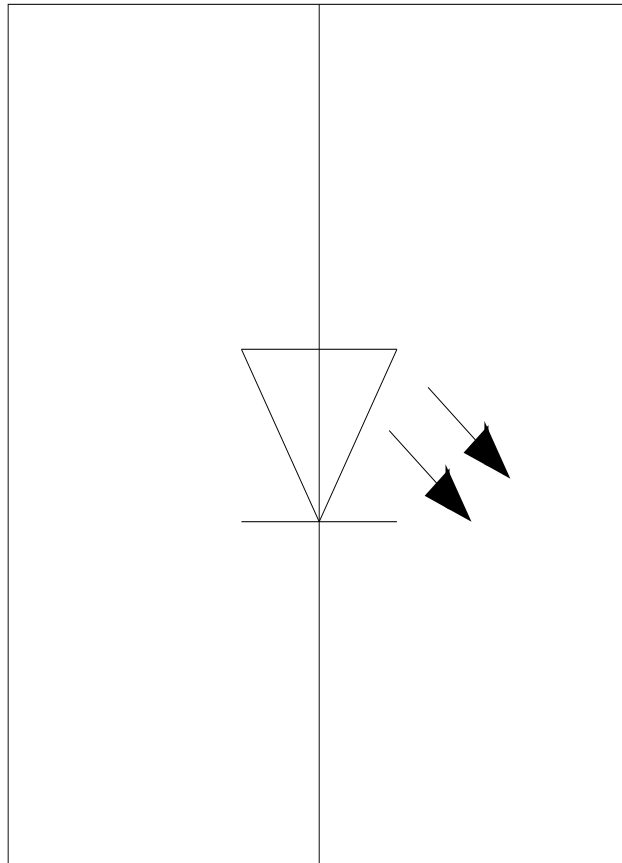

last modified:

4/1/2025 