


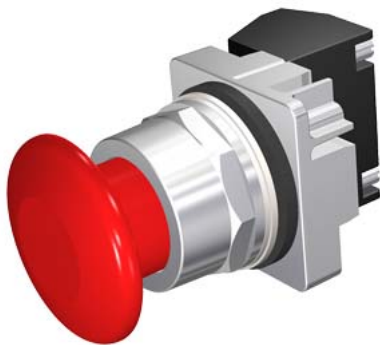

30mm Command/52, Chrome Finish Heavy Duty, Watertight/Oiltight Complete Metal Unit Push-Pull Operator Non-Illuminated Mushroom Head Cap Small 1 3/4" (44.5 mm) Plastic, Red 2 Position Maintained, Pull-to-Release with 1 N.O. - 1 N.C. Heavy Duty Contacts, A600/P600 UL Listed, CSA Certified NEMA 1, 3, 3R, 4, 4X, 12, 13 & Automotive Standards

| Enclosure                                              |                           |
|--------------------------------------------------------|---------------------------|
| number of command points                               | 1                         |
| delivery state as a kit                                | No                        |
| Actuator                                               |                           |
| material of the actuating element                      | plastic                   |
| number of contact modules                              | 1                         |
| type of unlocking device                               | pull-to-unlatch mechanism |
| number of switching positions                          | 2                         |
| Front ring                                             |                           |
| product component front ring                           | Yes                       |
| design of the front ring                               | standard                  |
| material of the front ring                             | metal                     |
| General technical data                                 |                           |
| product function positive opening                      | Yes                       |
| product component                                      |                           |
| • light source                                         | No                        |
| insulation voltage rated value                         | 600 V                     |
| surge voltage resistance rated value                   | 4 kV                      |
| protection class IP                                    | IP66                      |
| protection class IP of the terminal                    | IP20                      |
| thermal current                                        | 10 A                      |
| Net Weight                                             | 0.03 kg                   |
| Auxiliary circuit                                      |                           |
| number of NC contacts for auxiliary contacts           | 1                         |
| number of NO contacts for auxiliary contacts           | 1                         |
| operational current at AC-15                           |                           |
| • at 110 V rated value                                 | 60 A                      |
| • at 230 V rated value                                 | 30 A                      |
| • at 400 V rated value                                 | 15 A                      |
| • at 500 V rated value                                 | 12 A                      |
| Connections/ Terminals                                 |                           |
| type of electrical connection                          | screw terminal            |
| tightening torque of the screws in the bracket maximum | 20 N·m                    |
| tightening torque [lbf·in] with screw-type terminals   | 8 lbf·in                  |
| Ambient conditions                                     |                           |
| ambient temperature                                    |                           |
| • during operation                                     | -35 ... +70 °C            |
| • during storage                                       | -40 ... +85 °C            |
| Installation/ mounting/ dimensions                     |                           |

shape of the installation opening

round

#### Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information for data generation and storage

<https://support.industry.siemens.com/cs/ww/en/view/109995012>

Information- and Downloadcenter (Catalogs, Brochures,...)

<https://www.siemens.com/ic10>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=US2:52PP2W2A>

Cax online generator

<https://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=US2:52PP2W2A>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/US2:52PP2W2A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)

[https://www.automation.siemens.com/bilddb/cax\\_de.aspx?mlfb=US2:52PP2W2A&lang=en](https://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=US2:52PP2W2A&lang=en)

last modified:

10/23/2025 