

## UNIVERSAL CONTACTOR SUPPRESSOR

RC, 48VDC15VA/W

Art.No.: 20013

Weight: 0.028 kg

Country of origin: CZ

Model designation: RC-AD 22/48



48 V AC/DC

RC

For other configurations and voltages, please inquire.

### Link to Product

#### Illustration

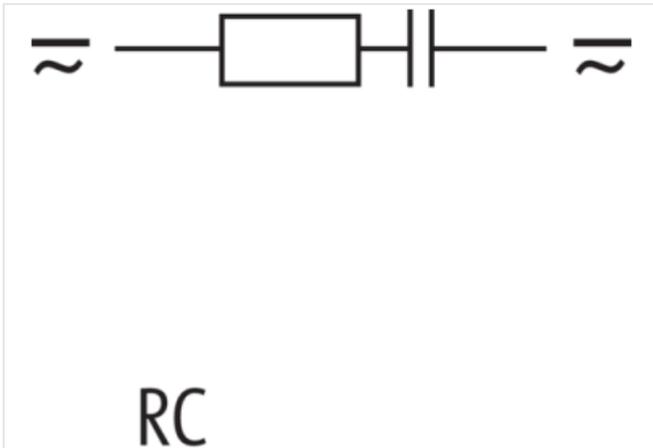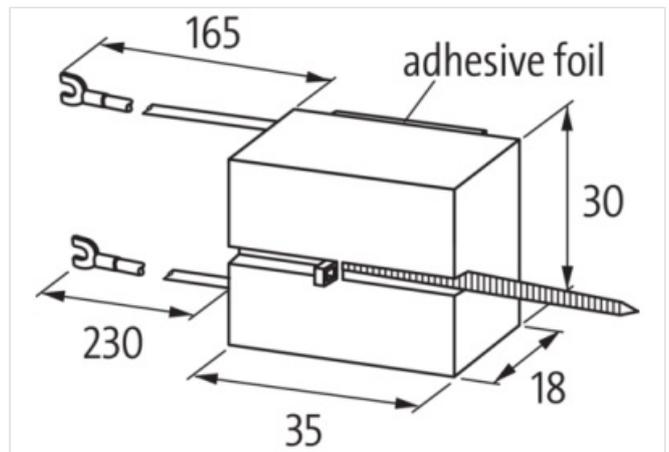

Product may differ from Image



#### Header

Material short text

RC-AD 22/48

#### Commercial data

URL Webshop

<https://shop.murrelektronik.com/20013>

GTIN	4048879020657
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879020657
Packaging unit	1

**Electrical data**

Damping factor	1.5x UN
Holding power max.	15 W

**Electrical data | Input**

Input voltage AC min.	24 V
Input voltage AC max.	48 V
Input voltage DC min.	24 V
Input voltage DC max.	48 V

**Installation | Connection**

Connection information	self-securing cable forks
------------------------	---------------------------

**Device protection | Media**

Flame resistance	flame retardant
------------------	-----------------

**Mechanical data | Material data**

Material housing	Plastic
Combustibility class housing (UL94)	V-0

**Mechanical data | Mounting data**

Height	35 mm
Width	30 mm
Depth	18 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	70 °C