

## UNIVERSAL CONTACTOR SUPPRESSOR

RC, 230VAC/DC/25VA/W

Art.No.: 20014

Weight: 0.030 kg

Country of origin: CZ

Model designation: RC-AD 047/230

230 V AC/DC

RC


For other configurations and voltages, please inquire.

### Link to Product

#### Illustration



Product may differ from Image

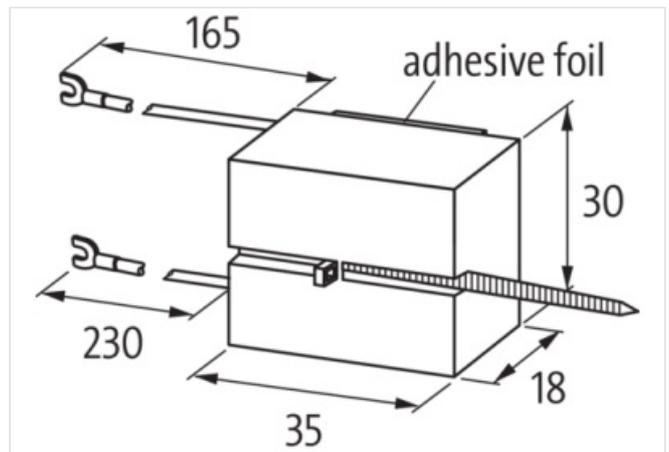

#### Header

Material short text RC-AD 047/230

#### Commercial data

URL Webshop	<a href="https://shop.murrelektronik.com/20014">https://shop.murrelektronik.com/20014</a>
GTIN	4048879020640
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013

ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879020640
Packaging unit	1

#### Electrical data

Damping factor	1.5x UN
Holding power max.	25 W

#### Electrical data | Input

Input voltage AC min.	110 V
Input voltage AC max.	250 V
Input voltage DC min.	110 V
Input voltage DC max.	250 V

#### Installation | Connection

Connection information	self-securing cable forks
------------------------	---------------------------

#### Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

#### Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0

#### Mechanical data | Mounting data

Height	35 mm
Width	30 mm
Depth	18 mm

#### Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C