

SUPPRESSOR FOR CONTACTORS

RC, 400 VAC/DC, 25 VA

Art.No.: 20032

Weight: 0.019 kg

Country of origin: CZ

Model designation: RC-BU1-015/400



400 V AC/DC

RC

For other configurations and voltages, please inquire.

Link to Product

Illustration

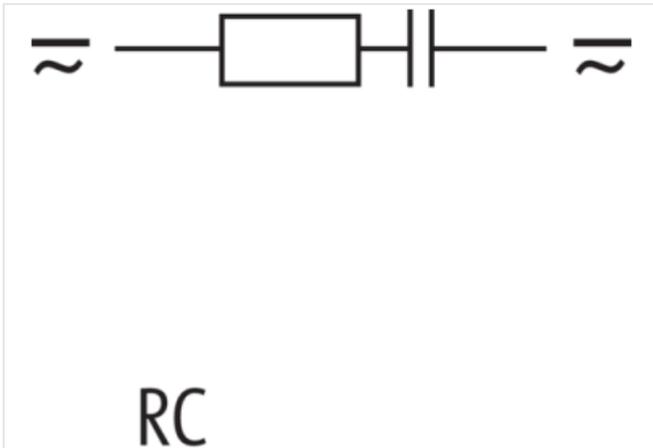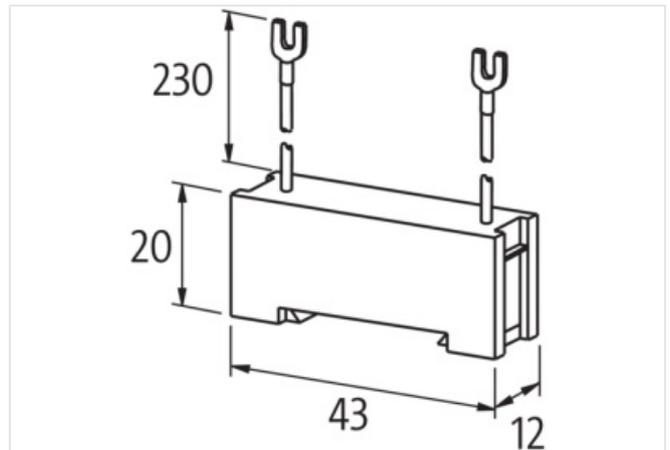

Product may differ from Image



Header

Material short text

RC-BU1-015/400

Commercial data

URL Webshop

<https://shop.murrelektronik.com/20032>

GTIN	4048879020619
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879020619
Packaging unit	1

Electrical data

Holding power max.	25 W
--------------------	------

Electrical data | Input

Input voltage AC min.	240 V
Input voltage AC max.	400 V

Mechanical data | Mounting data

Height	20 mm
Width	43 mm
Depth	12 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C