

UNIVERSAL CONTACTOR SUPPRESSOR

RC, 230VAC/DC/25VA/W

Art.No.: 20034

Weight: 0.020 kg

Country of origin: CZ

Model designation: RC-BU1-022/230-with ASA

230 V AC/DC

RC



For other configurations and voltages, please inquire.

without accessories, can be directly snapped onto DIN-rail, ASA adapter Art.-No. 20900 included.

ASA adapter Art.-No. 20900 (included)

Link to Product

Illustration

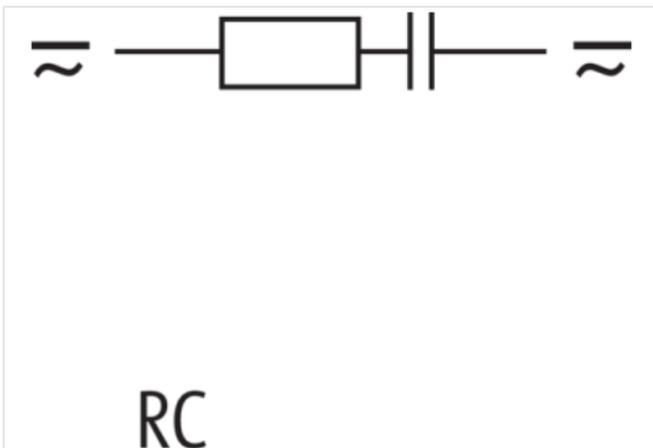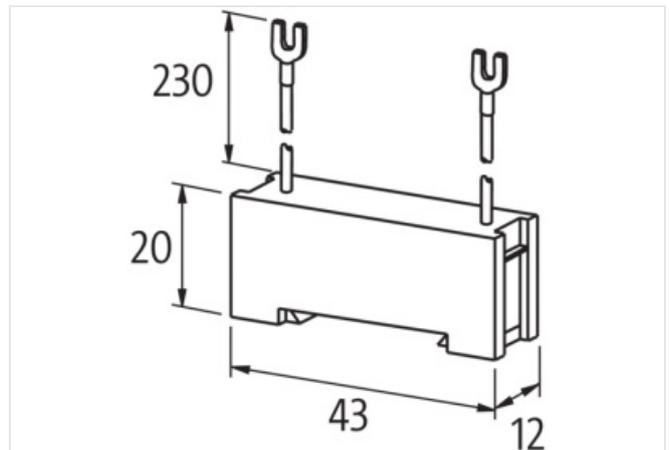

Product may differ from Image



Header

Material short text

RC-BU1-022/230-with ASA

Commercial data

The information in this Product-PDF has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2026-01-29

Murrelektronik Inc. | 1327 Northbrook Parkway, Suite 460 | Suwanee, GA 30024 | Fon +1 770 497-9292 | Fax +1 770 497-9391 | shop@murrinc.com | shop.murrinc.com

URL Webshop	https://shop.murrelektronik.com/20034
GTIN	4048879020596
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879020596
Packaging unit	1

Electrical data

Holding power max.	25 W
--------------------	------

Electrical data | Input

Input voltage AC min.	110 V
Input voltage AC max.	253 V
Input voltage DC min.	110 V
Input voltage DC max.	253 V

Mechanical data | Mounting data

Height	20 mm
Width	43 mm
Depth	12 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C