

UNIVERSAL CONTACTOR SUPPRESSOR

RC, 48VDC/15VA/W

Art.No.: 20100

Weight: 0.040 kg

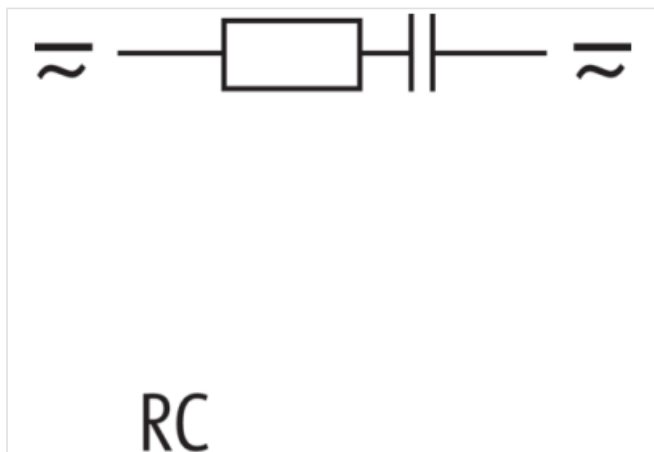
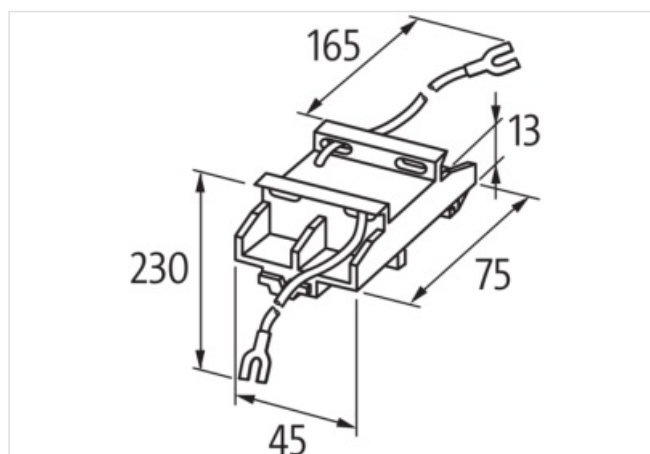
Country of origin: CZ

Model designation: H-RC-48/15-U

48 V AC/DC

RC

For other configurations and voltages, please inquire.

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

H-RC-48/15-U

Commercial data

URL Webshop

<https://shop.murrelektronik.com/20100>

GTIN	4048879020466
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879020466
Packaging unit	1
Electrical data	
Damping factor	1.5× UN
Holding power max.	15 W
Electrical data Input	
Input voltage AC min.	12 V
Input voltage AC max.	53 V
Input voltage DC min.	12 V
Input voltage DC max.	53 V
Installation Connection	
Connection information	self-securing cable forks
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Combustibility class housing (UL94)	V-0
Mechanical data Mounting data	
Height	45 mm
Width	75 mm
Depth	13 mm
Mounting method	geschnappt
Suitable for mounting type	(EN 60715), mounting rail
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C