

SUPPRESSOR FOR CONTACTORS

RC, 230 VAC/DC, 20 VA/W

Art.No.: 20682

Weight: 0.016 kg

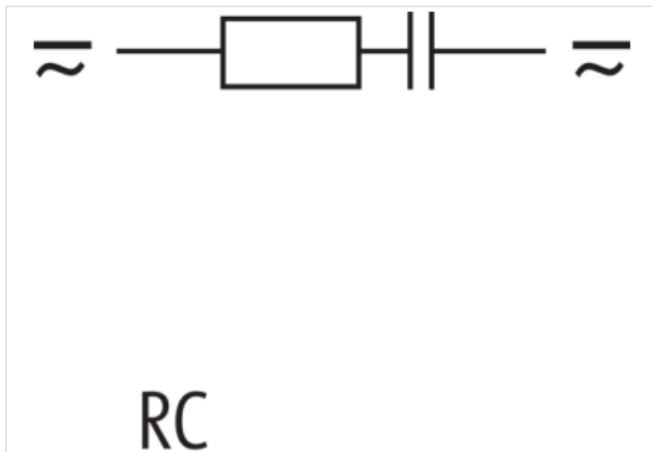
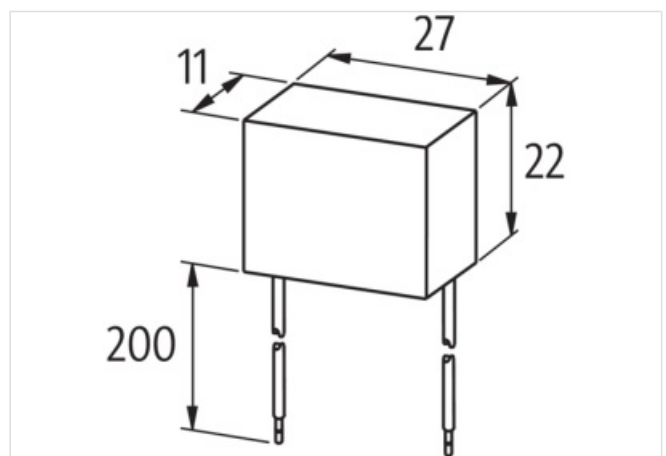
Country of origin: CZ

Model designation: RCF 22-220/230

230 V AC/DC

RC

For other configurations and voltages, please inquire.

Link to Product**Illustration**

Product may differ from Image

**Header**

Material short text

RCF 22-220/230

Commercial data

URL Webshop

<https://shop.murrelektronik.com/20682>

GTIN	4048879020343
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879020343
Packaging unit	1

Electrical data

Damping factor	1.5× UN
Holding power max.	20 W

Electrical data | Input

Input voltage AC min.	110 V
Input voltage AC max.	253 V
Input voltage DC min.	110 V
Input voltage DC max.	253 V

Installation | Connection

Connection information	flexible connection wires
------------------------	---------------------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0

Mechanical data | Mounting data

Height	22 mm
Width	27 mm
Depth	11 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C