

ALLEN-BRADLEY CONTACTOR SUPPRESSOR

RC, 240VAC/DC

Art.No.: 21143

Weight: 0.012 kg

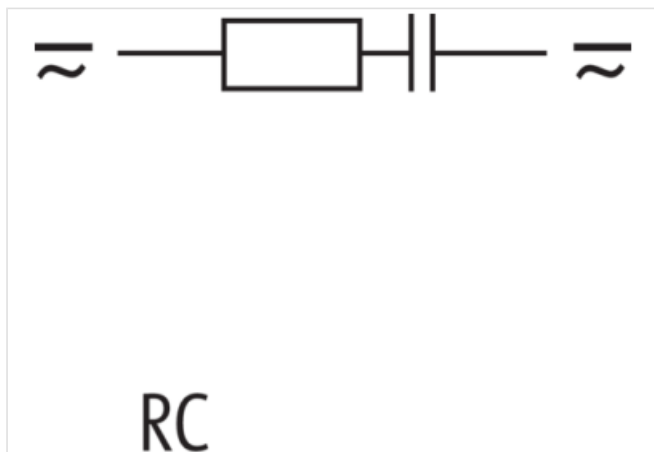
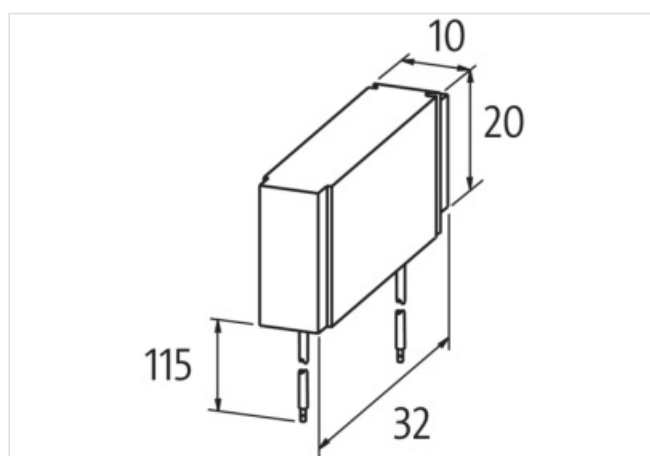
Country of origin: CZ

Model designation: SRC 4/240 VAC

230 V AC/DC

RC

For other configurations and voltages, please inquire.

Link to Product**Illustration**

Product may differ from Image

**Header**

Material short text

SRC 4/240 VAC

Commercial data

URL Webshop

<https://shop.murrelektronik.com/21143>

GTIN	4048879020060
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
customs tariff number	85363010
EAN	4048879020060
Packaging unit	1
Electrical data	
Damping factor	1.5× UN
Electrical data Input	
Input voltage AC min.	110 V
Input voltage AC max.	250 V
Input voltage DC min.	110 V
Input voltage DC max.	250 V
Installation Connection	
Connection information	flexible connection wires
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Combustibility class housing (UL94)	V-0
Mechanical data Mounting data	
Height	20 mm
Width	10 mm
Depth	32 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C