

## SIEMENS CONTACTOR SUPPRESSOR

RC, 24VDC

Art.No.: 21210

Weight: 0.010 kg

Country of origin: CZ

Model designation: RC 24/48 V



24 V AC/DC

RC

For other configurations and voltages, please inquire.

### Link to Product

#### Illustration

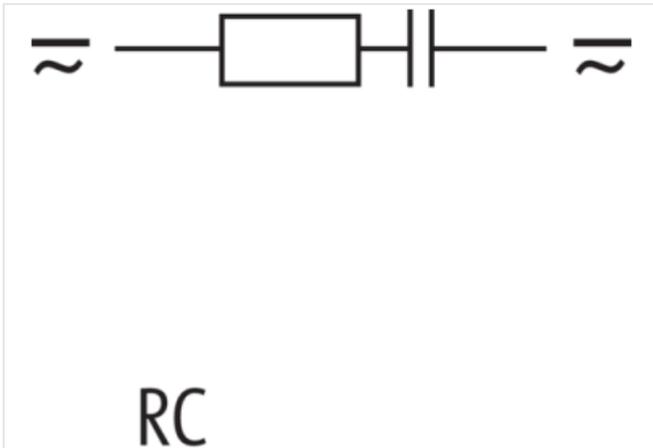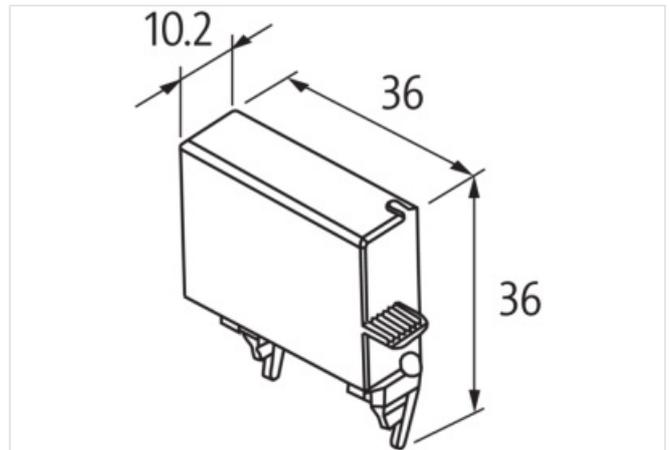

Product may differ from Image



#### Header

Material short text

RC 24/48 V

#### Commercial data

URL Webshop

<https://shop.murrelektronik.com/21210>

GTIN	4048879019965
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879019965
Packaging unit	1

**Electrical data | Input**

Input voltage AC min.	24 V
Input voltage AC max.	70 V
Input voltage DC min.	24 V
Input voltage DC max.	70 V

**Mechanical data | Mounting data**

Height	36 mm
Width	36 mm
Depth	10,2 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	70 °C