

MOTOR SUPPRESSOR

Varistor, 3x400VAC/20kW

Art.No.: 23015

Weight: 0.196 kg

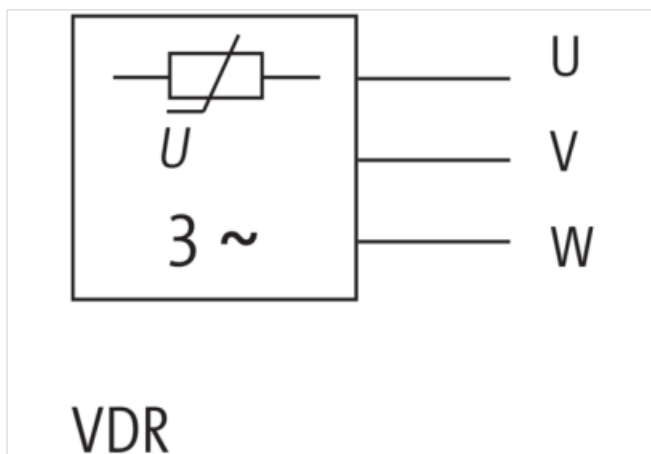
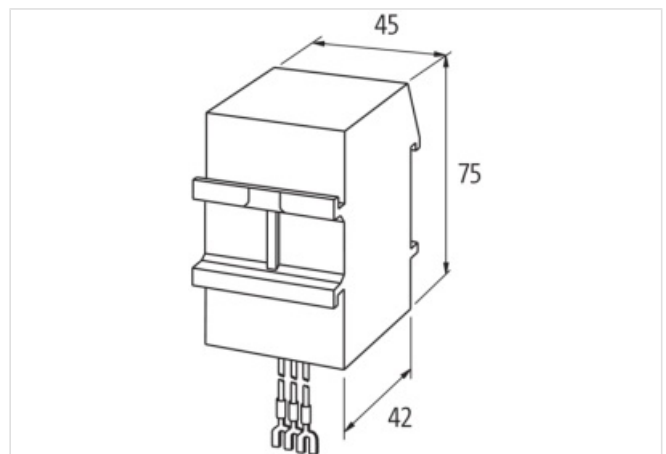
Country of origin: CZ

Model designation: HRC 3/VDR-400/20

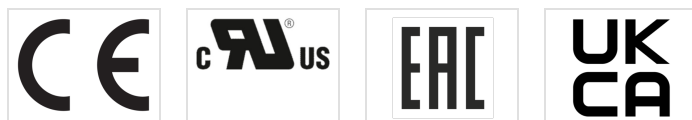
3 × 400 V AC

VDR

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

HRC 3/VDR-400/20

Commercial data

URL Webshop	https://shop.murrelektronik.com/23015
GTIN	4048879019552
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879019552
Packaging unit	1

Electrical data | Supply

Power frequency	10 ... 400 Hz
-----------------	---------------

Electrical data | Input

Input voltage AC	400 V
------------------	-------

Installation

Connection cross-section stranded/fine-stranded min.	0,5 mm ²
--	---------------------

Installation | Connection

Length single strands	250 mm
Connection information	Einzellitzen mit selbstsicherndem Gabelkabelschuh M4

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy

Mechanical data | Mounting data

Height	75 mm
Width	45 mm
Depth	42 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C