

MOTOR SUPPRESSOR

RC, 3x690VAC/10kW

Art.No.: 23017

Weight: 0.140 kg

Country of origin: CZ

Model designation: HRC 3/690-10

3× 690 V AC

RC


Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Link to Product

Illustration



Product may differ from Image

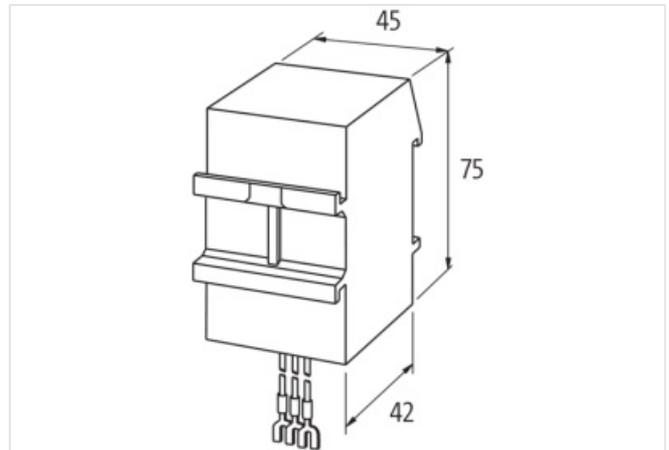

Header

Material short text HRC 3/690-10

Commercial data

URL Webshop	https://shop.murrelektronik.com/23017
GTIN	4048879019538
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013

ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879019538
Packaging unit	1

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Input voltage AC	690 V
------------------	-------

Installation

Connection cross-section stranded/fine-stranded min.	0,5 mm ²
--	---------------------

Installation | Connection

Length single strands	250 mm
Connection information	Einzellitzen mit selbstsicherndem Gabelkabelschuh M4

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy

Mechanical data | Mounting data

Height	75 mm
Width	45 mm
Depth	42 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C