

MOTOR SUPPRESSOR

RC, 3x575VAC/20kW

Art.No.: 23018

Weight: 0.189 kg

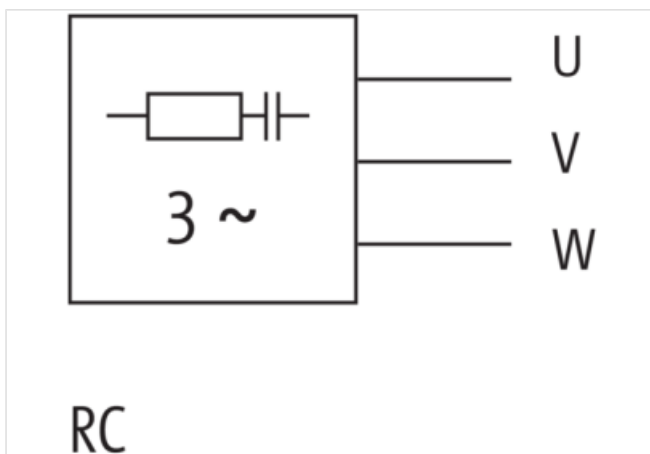
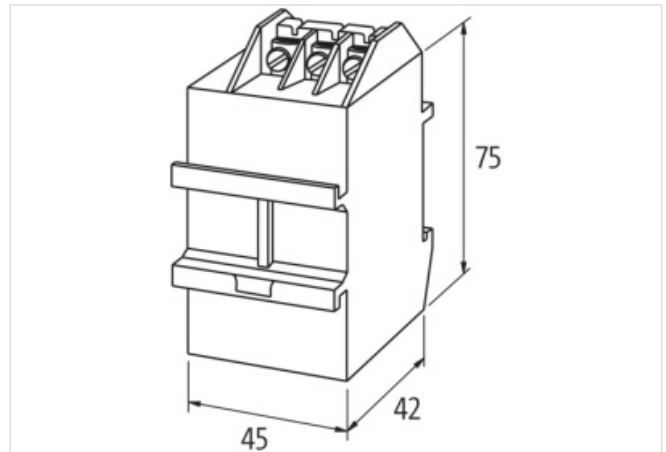
Country of origin: CZ

Model designation: HRC 3 /575-20 K

3× 575 V AC

RC

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

HRC 3 /575-20 K

Commercial data

URL Webshop	https://shop.murrelektronik.com/23018
GTIN	4048879019521
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879019521
Packaging unit	1

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Input voltage AC	575 V
------------------	-------

Installation

Connection cross-section solid min.	0,75 mm ²
Connection cross-section solid max.	2,5 mm ²

Installation | Connection

Family construction form	M4
Connection information	terminal

Installation | Pin assignment

No. of poles	3
--------------	---

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy

Mechanical data | Mounting data

Height	75 mm
Width	45 mm
Depth	42 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C