

## MOTOR SUPPRESSOR

RC, 3x575VAC/7,5kW

Art.No.: 23030

Weight: 0.108 kg

Country of origin: CZ

Model designation: RC 3/047-575 U- PG 9

RC

PG9



3 × 575 V AC

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

For DIN-rail mounting use 2×Art.-No. 20900 adapter feet  
approx. 500 mm, PVC cable 3 × 0.75 mm<sup>2</sup>

### [Link to Product](#)

#### Illustration

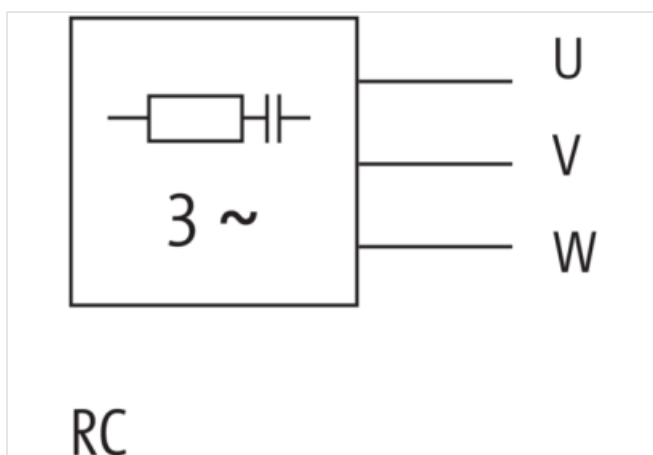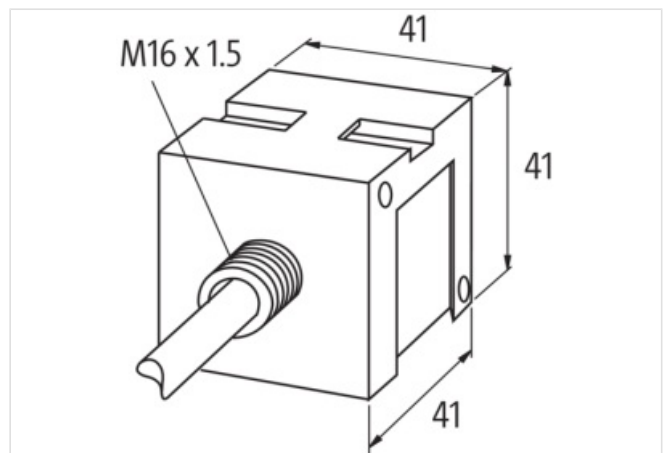

Product may differ from Image



#### Header

Material short text RC 3/047-575 U- PG 9

| Commercial data                          |                                                                                           |
|------------------------------------------|-------------------------------------------------------------------------------------------|
| URL Webshop                              | <a href="https://shop.murrelektronik.com/23030">https://shop.murrelektronik.com/23030</a> |
| GTIN                                     | 4048879019491                                                                             |
| ECLASS-6.0                               | 27371013                                                                                  |
| ECLASS-6.1                               | 27371013                                                                                  |
| ECLASS-7.0                               | 27371013                                                                                  |
| ECLASS-7.1                               | 27371013                                                                                  |
| ECLASS-8.0                               | 27371013                                                                                  |
| ECLASS-8.1                               | 27371013                                                                                  |
| ECLASS-9.0                               | 27371013                                                                                  |
| ECLASS-9.1                               | 27371013                                                                                  |
| ECLASS-10.0.1                            | 27371013                                                                                  |
| ECLASS-10.1                              | 27371013                                                                                  |
| ECLASS-11.0                              | 27371013                                                                                  |
| ECLASS-11.1                              | 27371013                                                                                  |
| ECLASS-12.0                              | 27371013                                                                                  |
| ECLASS-13.0                              | 27371013                                                                                  |
| ECLASS-14.0                              | 27371013                                                                                  |
| ETIM-5.0                                 | EC000683                                                                                  |
| ETIM-6.0                                 | EC000683                                                                                  |
| ETIM-7.0                                 | EC000683                                                                                  |
| ETIM-8.0                                 | EC000683                                                                                  |
| customs tariff number                    | 85363010                                                                                  |
| EAN                                      | 4048879019491                                                                             |
| Packaging unit                           | 1                                                                                         |
| Electrical data   Supply                 |                                                                                           |
| Power frequency                          | 50 ... 60 Hz                                                                              |
| Electrical data   Input                  |                                                                                           |
| Input voltage AC                         | 575 V                                                                                     |
| Installation                             |                                                                                           |
| Connection cross section max.            | 0,75 mm²                                                                                  |
| Installation   Connection                |                                                                                           |
| Family construction form                 | free cable end                                                                            |
| Installation   Pin assignment            |                                                                                           |
| No. of poles                             | 3                                                                                         |
| Device protection   Media                |                                                                                           |
| Flame resistance                         | flame retardant                                                                           |
| Mechanical data   Material data          |                                                                                           |
| Material housing                         | Plastic                                                                                   |
| Combustibility class housing (UL94)      | V-0                                                                                       |
| Material potting compound                | 2-component epoxy                                                                         |
| Mechanical data   Mounting data          |                                                                                           |
| Height                                   | 41 mm                                                                                     |
| Width                                    | 41 mm                                                                                     |
| Depth                                    | 41 mm                                                                                     |
| Mounting method                          | geschnappt                                                                                |
| Suitable for mounting type               | Mounting rail TH35, (EN 60715)                                                            |
| Environmental characteristics   Climatic |                                                                                           |
| Operating temperature min.               | -20 °C                                                                                    |

Operating temperature max. 60 °C