

MOTOR SUPPRESSOR

RC, 3x575VAC/7,5kW

Art.No.: 23035

Weight: 0.110 kg

Country of origin: CZ

Model designation: RC 3 U-575/7,5 M16 X 1,5

3× 575 V AC



RC

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

For DIN-rail mounting use 2×Art.-No. 20900 adapter feet
approx. 500 mm, PVC cable 3× 0.75 mm²

[Link to Product](#)

Illustration

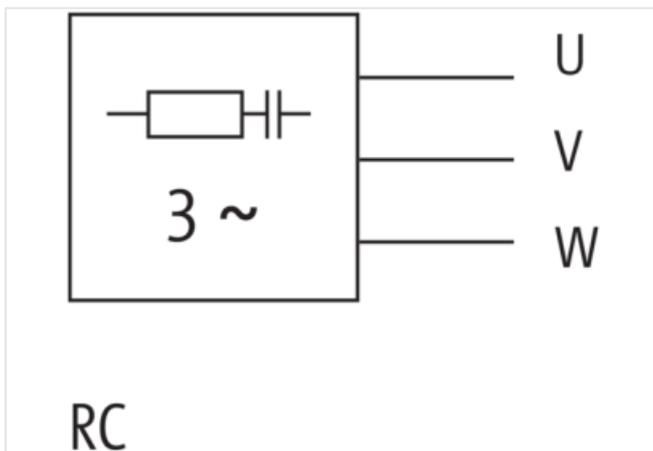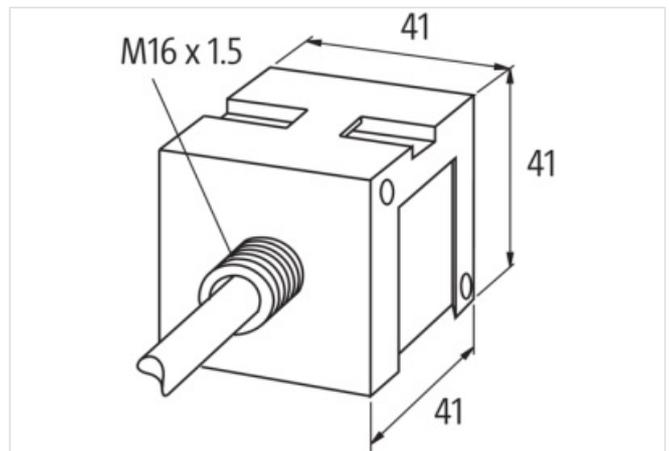

Product may differ from Image



Header

Material short text

RC 3 U-575/7,5 M16 X 1,5

Commercial data	
URL Webshop	https://shop.murrelektronik.com/23035
GTIN	4048879019484
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879019484
Packaging unit	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage AC	575 V
Installation	
Connection cross section max.	0,75 mm ²
Installation Connection	
Family construction form	free cable end
Installation Pin assignment	
No. of poles	3
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy
Mechanical data Mounting data	
Height	41 mm
Width	41 mm
Depth	41 mm
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C