

MOTOR SUPPRESSOR

RC, 3x575VAC/7,5kW

Art.No.: 230563

Weight: 0.124 kg

Country of origin: CZ

Model designation: HRC 3/047-575V/7,5 with AEH

3× 575 V AC



RC

with ferrule ends

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)

Illustration

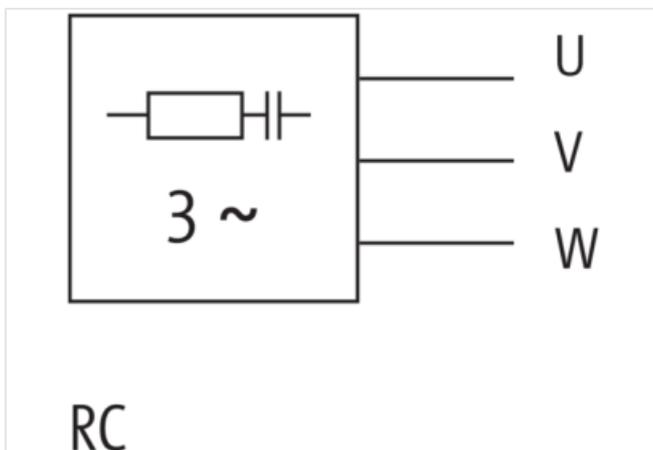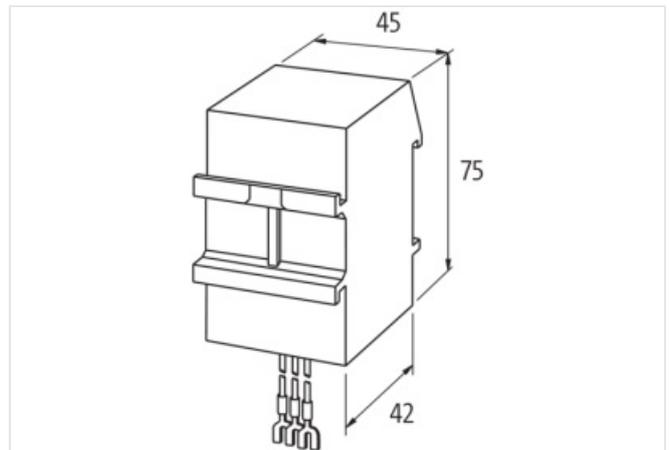

Product may differ from Image



Header

Material short text

HRC 3/047-575V/7,5 with AEH

Commercial data

The information in this Product-PDF has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2026-02-17

Murrelektronik Inc. | 1327 Northbrook Parkway, Suite 460 | Suwanee, GA 30024 | Fon +1 770 497-9292 | Fax +1 770 497-9391 | shop@murrinc.com | shop.murrinc.com

URL Webshop	https://shop.murrelektronik.com/230563
GTIN	4048879015820
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879015820
Packaging unit	1

Electrical data | Supply

Power frequency	50 ... 60 Hz
-----------------	--------------

Electrical data | Input

Input voltage AC	575 V
------------------	-------

Installation

Connection cross-section stranded/fine-stranded min.	0,5 mm ²
--	---------------------

Installation | Connection

Length single strands	250 mm
Connection information	Einzellitzen mit selbstsicherndem Gabelkabelschuh M4

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy

Mechanical data | Mounting data

Height	75 mm
Width	45 mm
Depth	42 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C