

MOTOR SUPPRESSOR

RC, 3x690VAC/7,5kW

Art.No.: 23104

Weight: 0.160 kg

Country of origin: CZ

Model designation: RC 3 BUG/690-7,5

3× 400 V AC

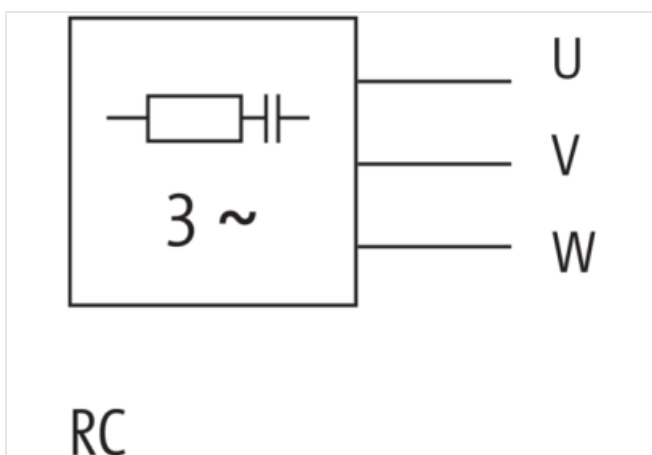
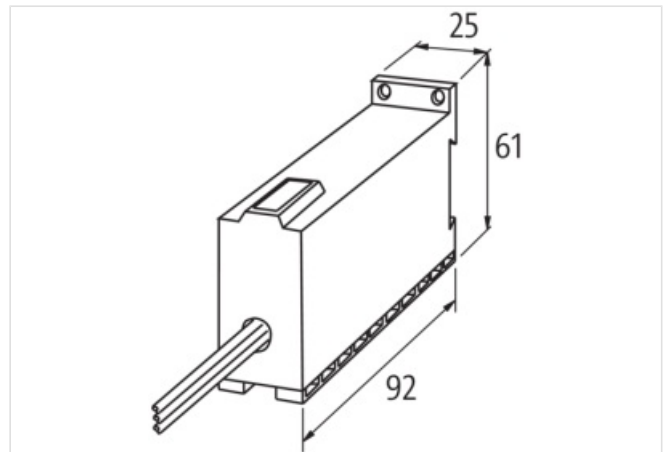
3× 575 V AC

3× 690 V AC

RC

For DIN-rail mounting use 2×Art.-No. 20900 adapter feet

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text RC 3 BUG/690-7,5

Commercial data	
URL Webshop	https://shop.murrelektronik.com/23104
GTIN	4048879019347
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879019347
Packaging unit	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage AC	690 V
Installation	
Connection cross section max.	1 mm ²
Installation Connection	
Length single strands	500 mm
Connection information	Single strands
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy
Mechanical data Mounting data	
Height	92 mm
Width	61 mm
Depth	25 mm
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C