

**MOTOR SUPPRESSOR**

Varistor, 3x400VAC/4kW

Art.No.: 23110

Weight: 0.030 kg

Country of origin: CZ

Model designation: RC 3R-400/4-PG9

3× 400 V AC

VDR



isolated M6

PG9

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)

**Illustration**

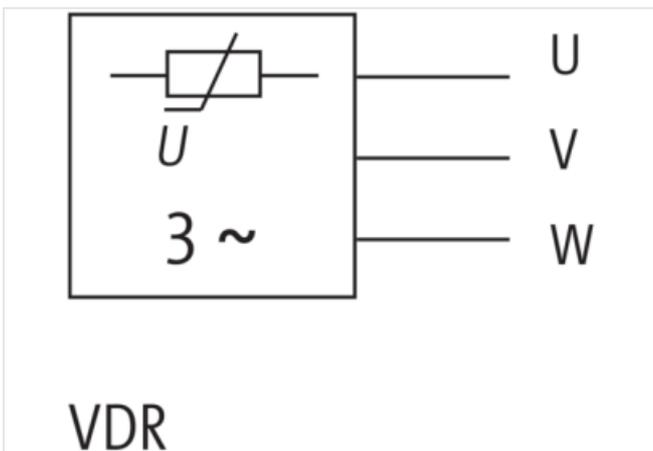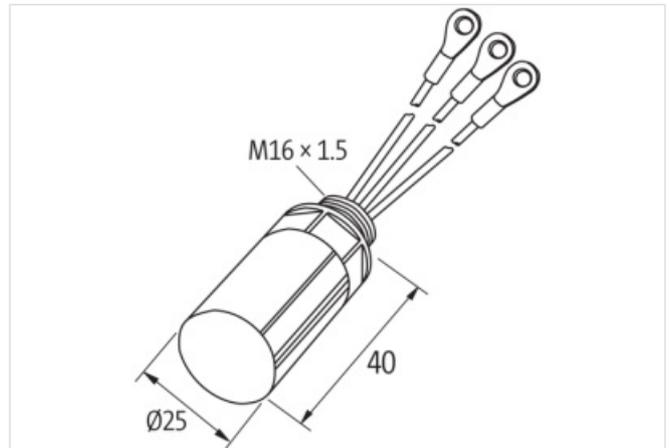

Product may differ from Image



**Header**

Material short text

RC 3R-400/4-PG9

<b>Commercial data</b>	
URL Webshop	<a href="https://shop.murrelektronik.com/23110">https://shop.murrelektronik.com/23110</a>
GTIN	4048879019316
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879019316
Packaging unit	1
<b>Electrical data   Supply</b>	
Power frequency	10 ... 400 Hz
<b>Electrical data   Input</b>	
Input voltage AC	400 V
<b>Installation</b>	
Connection cross section max.	0,5 mm <sup>2</sup>
<b>Installation   Connection</b>	
Ring terminals	M6, isolated
Length single strands	100 mm
Connection information	Single strands
<b>Device protection   Media</b>	
Flame resistance	flame retardant
<b>Mechanical data   Material data</b>	
Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy
<b>Mechanical data   Mounting data</b>	
Height	25 mm
Width	25 mm
Depth	40 mm
Mounting method	inserted
Suitable for mounting type	Motorklemmkasten
<b>Environmental characteristics   Climatic</b>	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C