

**MOTOR SUPPRESSOR**

Varistor, 3x400VAC/7,5kW

Art.No.: 23111

Weight: 0.030 kg

Country of origin: CZ

Model designation: RC 3 R-400/7,5-PG9

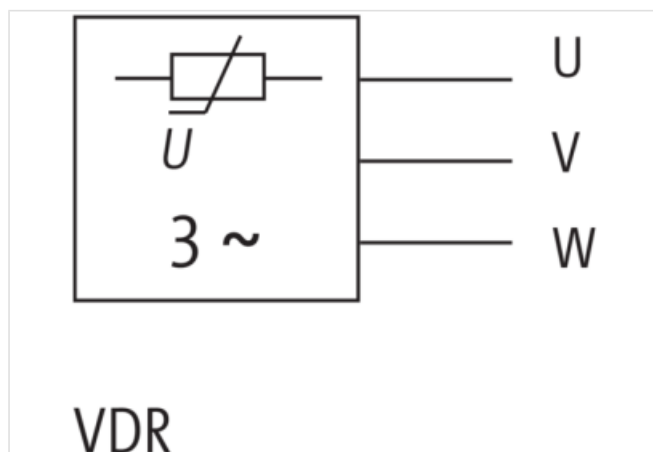
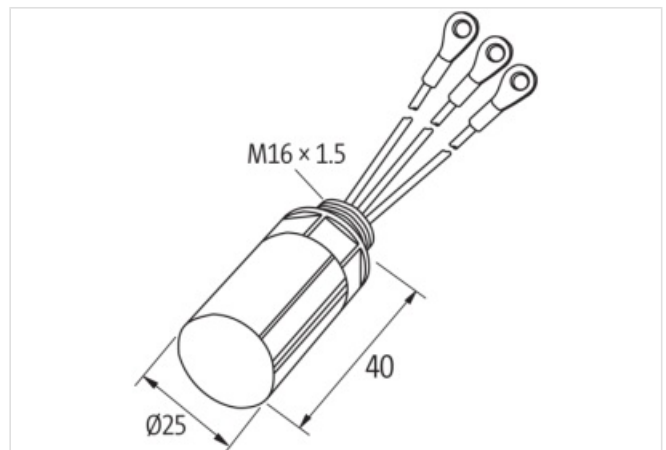
3× 400 V AC

VDR

isolated M6

PG9

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

RC 3 R-400/7,5-PG9

| Commercial data                          |                                                                                           |
|------------------------------------------|-------------------------------------------------------------------------------------------|
| URL Webshop                              | <a href="https://shop.murrelektronik.com/23111">https://shop.murrelektronik.com/23111</a> |
| GTIN                                     | 4048879019309                                                                             |
| ECLASS-6.0                               | 27371013                                                                                  |
| ECLASS-6.1                               | 27371013                                                                                  |
| ECLASS-7.0                               | 27371013                                                                                  |
| ECLASS-7.1                               | 27371013                                                                                  |
| ECLASS-8.0                               | 27371013                                                                                  |
| ECLASS-8.1                               | 27371013                                                                                  |
| ECLASS-9.0                               | 27371013                                                                                  |
| ECLASS-9.1                               | 27371013                                                                                  |
| ECLASS-10.0.1                            | 27371013                                                                                  |
| ECLASS-10.1                              | 27371013                                                                                  |
| ECLASS-11.0                              | 27371013                                                                                  |
| ECLASS-11.1                              | 27371013                                                                                  |
| ECLASS-12.0                              | 27371013                                                                                  |
| ECLASS-13.0                              | 27371013                                                                                  |
| ECLASS-14.0                              | 27371013                                                                                  |
| ETIM-5.0                                 | EC000683                                                                                  |
| ETIM-6.0                                 | EC000683                                                                                  |
| ETIM-7.0                                 | EC000683                                                                                  |
| ETIM-8.0                                 | EC000683                                                                                  |
| customs tariff number                    | 85363010                                                                                  |
| EAN                                      | 4048879019309                                                                             |
| Packaging unit                           | 1                                                                                         |
| Electrical data   Supply                 |                                                                                           |
| Power frequency                          | 10 ... 400 Hz                                                                             |
| Electrical data   Input                  |                                                                                           |
| Input voltage AC                         | 400 V                                                                                     |
| Installation                             |                                                                                           |
| Connection cross section max.            | 0,5 mm <sup>2</sup>                                                                       |
| Installation   Connection                |                                                                                           |
| Ring terminals                           | M6, isolated                                                                              |
| Length single strands                    | 100 mm                                                                                    |
| Connection information                   | Single strands                                                                            |
| Device protection   Media                |                                                                                           |
| Flame resistance                         | flame retardant                                                                           |
| Mechanical data   Material data          |                                                                                           |
| Material housing                         | Plastic                                                                                   |
| Combustibility class housing (UL94)      | V-0                                                                                       |
| Material potting compound                | 2-component epoxy                                                                         |
| Mechanical data   Mounting data          |                                                                                           |
| Height                                   | 25 mm                                                                                     |
| Width                                    | 25 mm                                                                                     |
| Depth                                    | 40 mm                                                                                     |
| Mounting method                          | inserted                                                                                  |
| Suitable for mounting type               | Motorklemmkasten                                                                          |
| Environmental characteristics   Climatic |                                                                                           |
| Operating temperature min.               | -20 °C                                                                                    |
| Operating temperature max.               | 60 °C                                                                                     |