

MOTOR SUPPRESSOR

RC, 3x400...575VAC/4kW

Art.No.: 23141

Weight: 0.075 kg

Country of origin: CZ

Model designation: RC 3 RG-400...575/4-M20 X 1,5 M6

3× 400 V AC



3× 575 V AC

RC

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)

Illustration

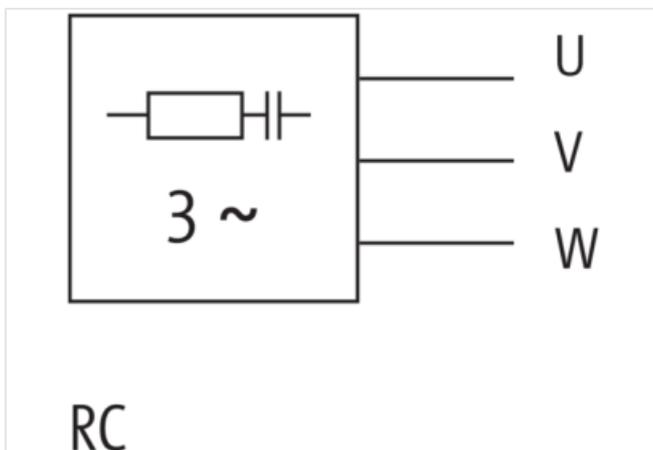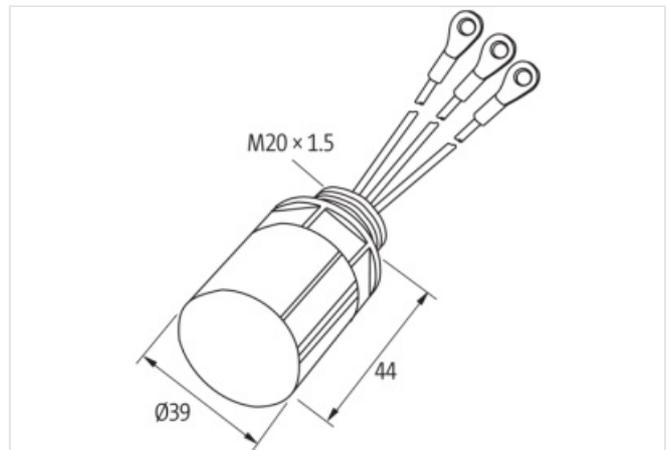

Product may differ from Image



Header

Material short text

RC 3 RG-400...575/4-M20 X 1,5 M6

Commercial data

The information in this Product-PDF has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2026-02-16

Murrelektronik Inc. | 1327 Northbrook Parkway, Suite 460 | Suwanee, GA 30024 | Fon +1 770 497-9292 | Fax +1 770 497-9391 | shop@murrinc.com | shop.murrinc.com

| | |
|-----------------------|---|
| URL Webshop | https://shop.murrelektronik.com/23141 |
| GTIN | 4048879019149 |
| ECLASS-6.0 | 27371013 |
| ECLASS-6.1 | 27371013 |
| ECLASS-7.0 | 27371013 |
| ECLASS-7.1 | 27371013 |
| ECLASS-8.0 | 27371013 |
| ECLASS-8.1 | 27371013 |
| ECLASS-9.0 | 27371013 |
| ECLASS-9.1 | 27371013 |
| ECLASS-10.0.1 | 27371013 |
| ECLASS-10.1 | 27371013 |
| ECLASS-11.0 | 27371013 |
| ECLASS-11.1 | 27371013 |
| ECLASS-12.0 | 27371013 |
| ECLASS-13.0 | 27371013 |
| ECLASS-14.0 | 27371013 |
| ETIM-5.0 | EC000683 |
| ETIM-6.0 | EC000683 |
| ETIM-7.0 | EC000683 |
| ETIM-8.0 | EC000683 |
| customs tariff number | 85363010 |
| EAN | 4048879019149 |
| Packaging unit | 1 |

Electrical data | Supply

| | |
|-----------------|--------------|
| Power frequency | 50 ... 60 Hz |
|-----------------|--------------|

Electrical data | Input

| | |
|------------------|-------|
| Input voltage AC | 575 V |
|------------------|-------|

Installation

| | |
|-------------------------------|-------------------|
| Connection cross section max. | 1 mm ² |
|-------------------------------|-------------------|

Installation | Connection

| | |
|------------------------|----------------|
| Ring terminals | M6, isolated |
| Length single strands | 150 mm |
| Connection information | Single strands |

Device protection | Media

| | |
|------------------|-----------------|
| Flame resistance | flame retardant |
|------------------|-----------------|

Mechanical data | Material data

| | |
|-------------------------------------|-------------------|
| Material housing | Plastic |
| Combustibility class housing (UL94) | V-0 |
| Material potting compound | 2-component epoxy |

Mechanical data | Mounting data

| | |
|----------------------------|------------------|
| Height | 39 mm |
| Width | 39 mm |
| Depth | 44 mm |
| Mounting method | inserted |
| Suitable for mounting type | Motorklemmkasten |

Environmental characteristics | Climatic

| | |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 60 °C |