

MOTOR SUPPRESSOR

Varistor, 3x690VAC/7,5kW

Art.No.: 23174

Weight: 0.058 kg

Country of origin: CZ

Model designation: RC 3 R-690/7,5-M16 X 1,5

3× 690 V AC



VDR

Wire diameter 1.5 mm²

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)

Illustration

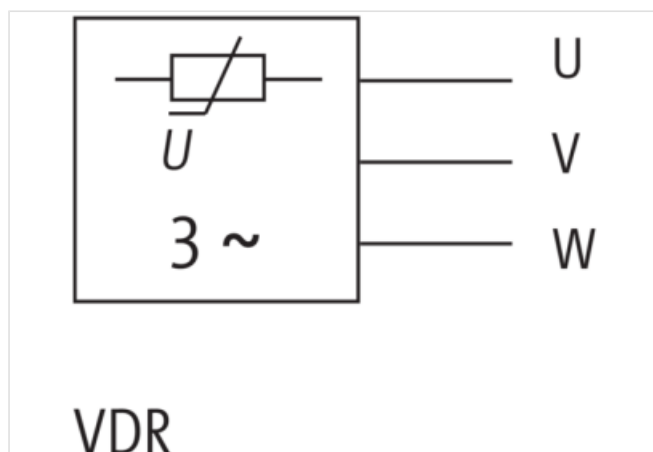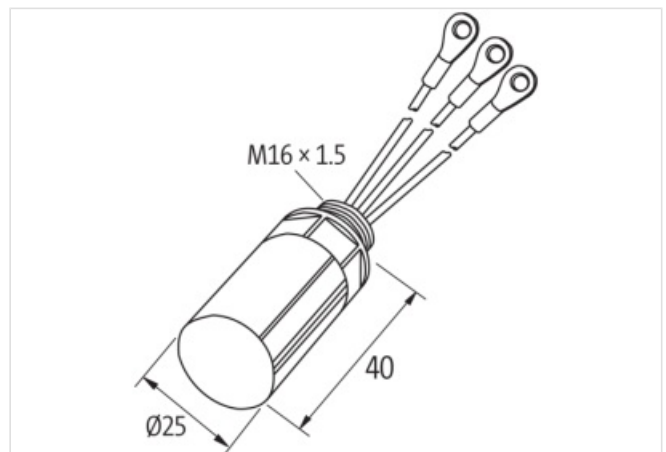

Product may differ from Image



Header

Material short text

RC 3 R-690/7,5-M16 X 1,5

Commercial data

URL Webshop	https://shop.murrelektronik.com/23174
GTIN	4048879018890
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879018890
Packaging unit	1

Electrical data | Supply

Power frequency	10 ... 400 Hz
-----------------	---------------

Electrical data | Input

Input voltage AC	690 V
------------------	-------

Installation

Connection cross section max.	0,5 mm ²
-------------------------------	---------------------

Installation | Connection

Ring terminals	M6, isolated
Length single strands	100 mm
Connection information	Single strands

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy

Mechanical data | Mounting data

Height	25 mm
Width	25 mm
Depth	40 mm
Mounting method	inserted
Suitable for mounting type	Motorklemmkasten

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C