

MOTOR SUPPRESSOR

RC, 3x575VAC/5,5kW

Art.No.: 23181

Weight: 0.080 kg

Country of origin: CZ

Model designation: RC 3 RT/022-575


3x 575 V AC

RC

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

Link to Product

Illustration

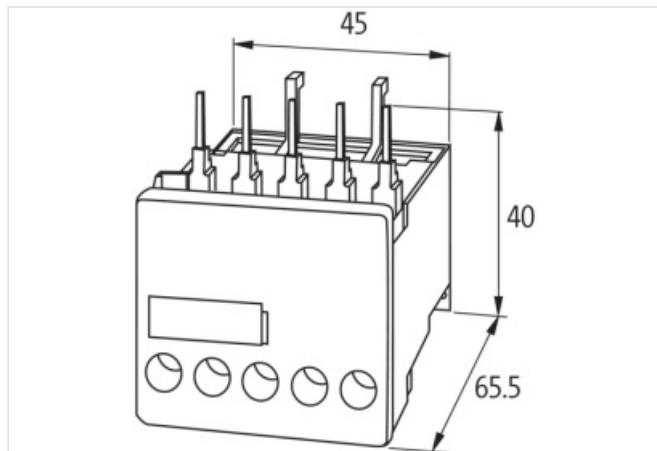

Product may differ from Image



Header

Material short text RC 3 RT/022-575

Commercial data

URL Webshop	https://shop.murrelektronik.com/23181
GTIN	4048879018869
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013

ECCLASS-13.0	27371013
ECCLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879018869
Packaging unit	1
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage AC	575 V
Installation Connection	
Connection information	fits directly into SIRIUS contactors, size 00
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Combustibility class housing (UL94)	V-0
Mechanical data Mounting data	
Height	40 mm
Width	45 mm
Depth	65,5 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C