

EMC SUPPRESSOR FOR MOTOR

RC 3 BU/022-575VAC, star, AWG 20

Art.No.: 236116

Weight: 0.040 kg

Country of origin: CZ

Model designation: RC 3 BU/022-575/4

3× 400 V AC

3× 575 V AC



RC

For DIN-rail mounting use Art.-No. 20900 adapter feet

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)

Illustration

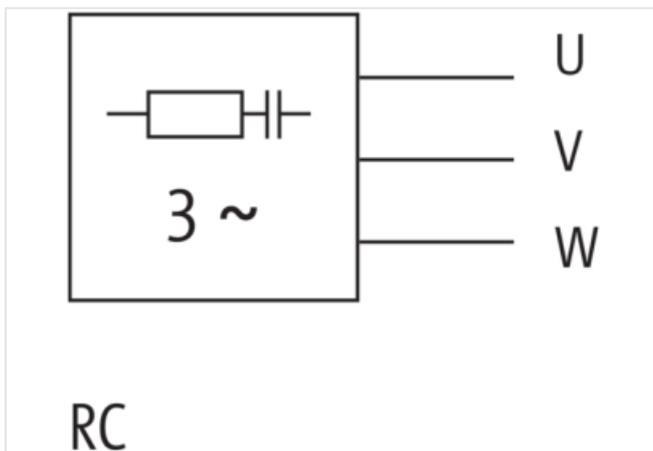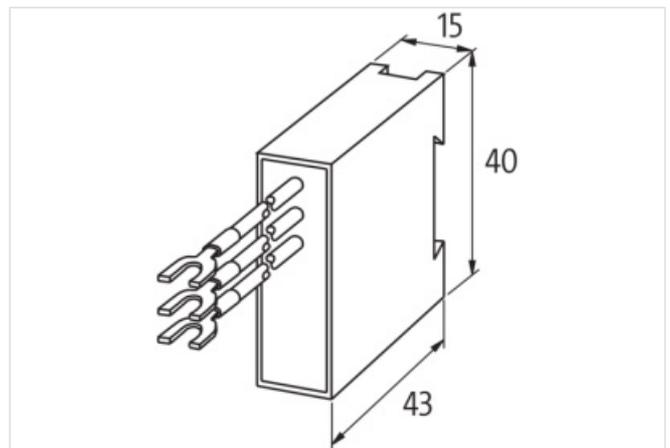

Product may differ from Image



Header

Material short text

RC 3 BU/022-575/4

Commercial data	
URL Webshop	https://shop.murrelektronik.com/236116
GTIN	4048879015295
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879015295
Packaging unit	10
Electrical data Supply	
Power frequency	50 ... 60 Hz
Electrical data Input	
Input voltage AC	575 V
Installation	
Connection cross-section solid max.	0,5 mm ²
Installation Connection	
Length single strands	70 mm
Connection information	Single strands
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy
Mechanical data Mounting data	
Height	43 mm
Width	15 mm
Depth	40 mm
Mounting method	geschnappt
Suitable for mounting type	Mounting rail TH35, (EN 60715)
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C