

EMC SUPPRESSOR FOR MOTOR

RC 3 R-575/4, M16x1,5/ AWG 20/VDR"

Art.No.: 236161

Weight: 0.034 kg

Country of origin: CZ

Model designation: RC 3 R-575/4 M16X1,5/RKS-M4

3× 575 V AC



VDR

M16×1.5 mm

Suppressors for other voltages, frequencies, and motor ratings available on request. Do not use RC motor suppressors with frequency inverters.

[Link to Product](#)

Illustration

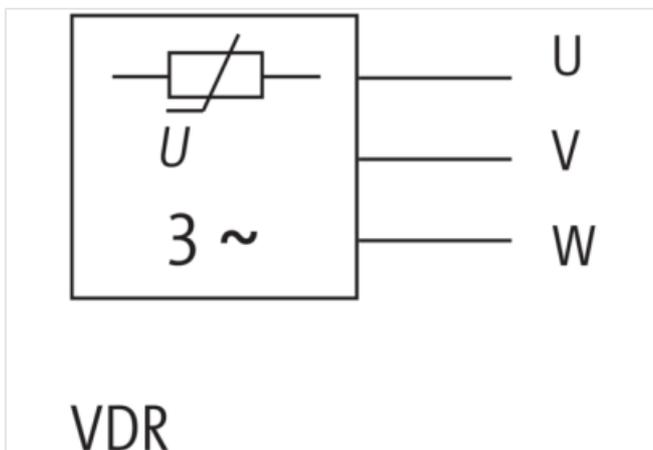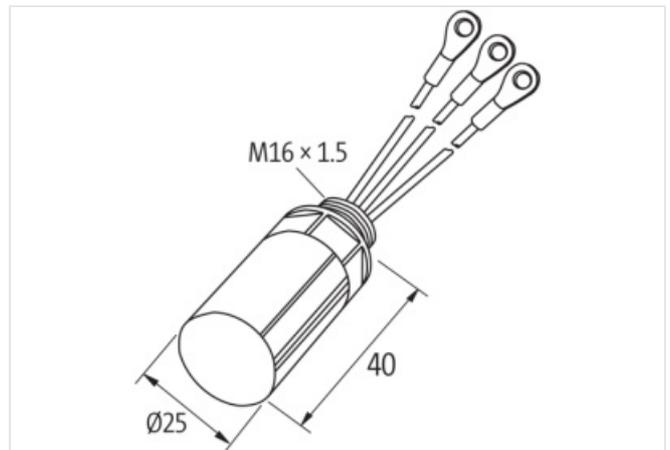

Product may differ from Image



Header

Material short text

RC 3 R-575/4 M16X1,5/RKS-M4

Commercial data

The information in this Product-PDF has been compiled with the utmost care.

Liability for the correctness completeness and topicality of the information is restricted to gross negligence. Version: 2026-02-16

Murrelektronik Inc. | 1327 Northbrook Parkway, Suite 460 | Suwanee, GA 30024 | Fon +1 770 497-9292 | Fax +1 770 497-9391 | shop@murrinc.com | shop.murrinc.com

URL Webshop	https://shop.murrelektronik.com/236161
GTIN	4048879015035
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879015035
Packaging unit	10

Electrical data | Input

Input voltage AC	575 V
------------------	-------

Installation

Connection cross section max.	0,5 mm ²
-------------------------------	---------------------

Installation | Connection

Ring terminals	M4, isolated
Length single strands	100 mm
Connection information	Single strands

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0
Material potting compound	2-component epoxy

Mechanical data | Mounting data

Height	25 mm
Width	25 mm
Depth	40 mm
Mounting method	inserted
Suitable for mounting type	Motorklemmkasten

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C