

SIEMENS CONTACTOR SUPPRESSOR

Varistor, 24VAC/DC

Art.No.: 26090

Weight: 0.040 kg

Country of origin: CZ

Model designation: H-VG 1/24



24 V AC/DC

VDR

For other configurations and voltages, please inquire.

Link to Product

Illustration

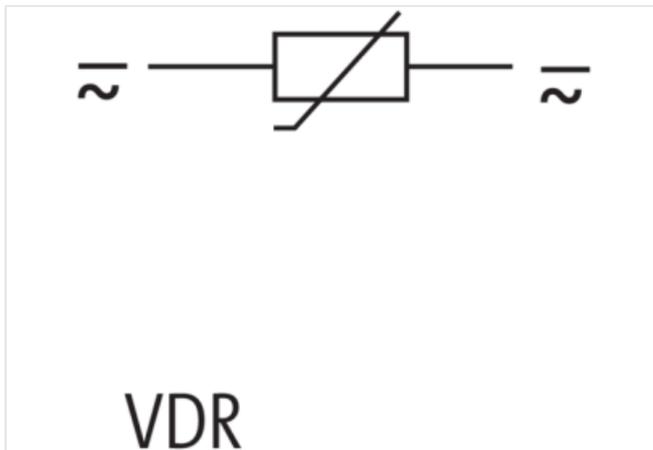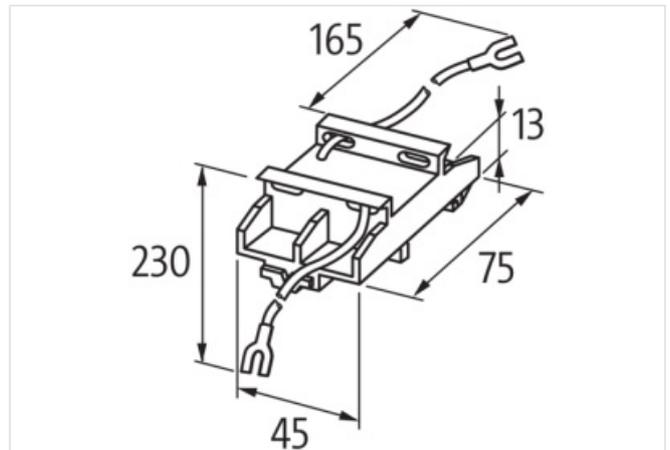

Product may differ from Image



Header

Material short text

H-VG 1/24

Commercial data

URL Webshop

<https://shop.murrelektronik.com/26090>

GTIN	4048879018371
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879018371
Packaging unit	1

Electrical data

Damping factor	1.5× UN
Holding power max.	50 W

Electrical data | Input

Input voltage AC min.	12 V
Input voltage AC max.	30 V
Input voltage DC min.	12 V
Input voltage DC max.	30 V

Installation | Connection

Connection information	self-securing cable forks
------------------------	---------------------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0

Mechanical data | Mounting data

Height	75 mm
Width	45 mm
Depth	13 mm
Mounting method	geschnappt
Suitable for mounting type	(EN 60715), mounting rail

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C