

SUPPRESSOR FOR CONTACTORS

Diode combination, 24 VDC, 25 W

Art.No.: 26120

Weight: 0.012 kg

Country of origin: CZ

Model designation: LG-AZ 1/24



24 V DC

Z-Diode

For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

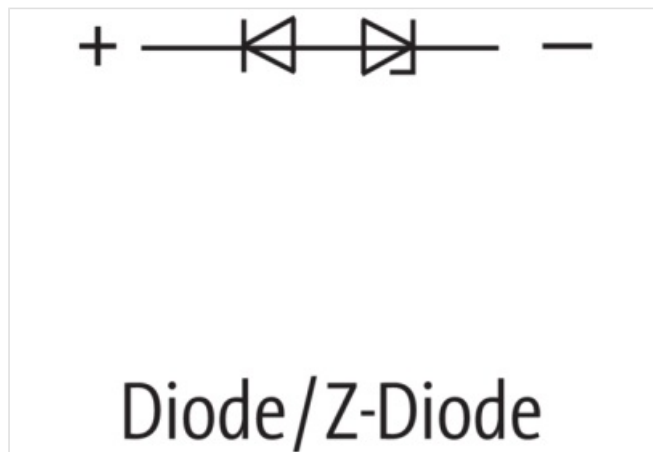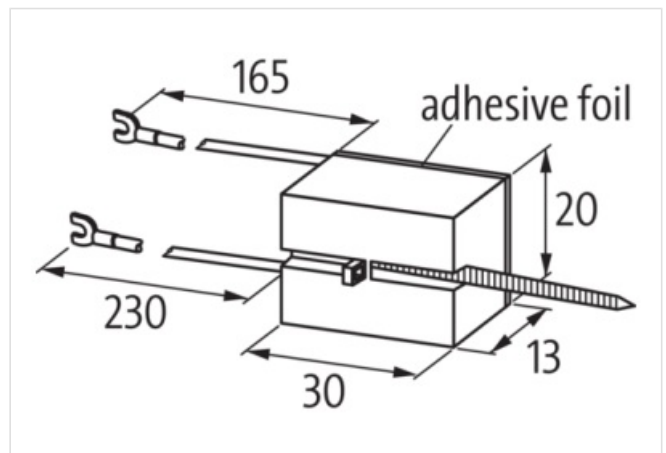

Product may differ from Image



Header

Material short text

LG-AZ 1/24

Commercial data

URL Webshop

<https://shop.murrelektronik.com/26120>

GTIN	4048879018272
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879018272
Packaging unit	1
Electrical data	
Damping factor	1.5× UN
Holding power max.	25 W
Electrical data Input	
Input voltage DC min.	0 V
Input voltage DC max.	240 V
Installation Connection	
Connection information	self-securing cable forks
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	Plastic
Combustibility class housing (UL94)	V-0
Mechanical data Mounting data	
Height	30 mm
Width	20 mm
Depth	13 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	70 °C