

**SUPPRESSOR FOR CONTACTORS**

VDR, 24 VAC/DC, 50 VA/W

Art.No.: 26180

Weight: 0.014 kg

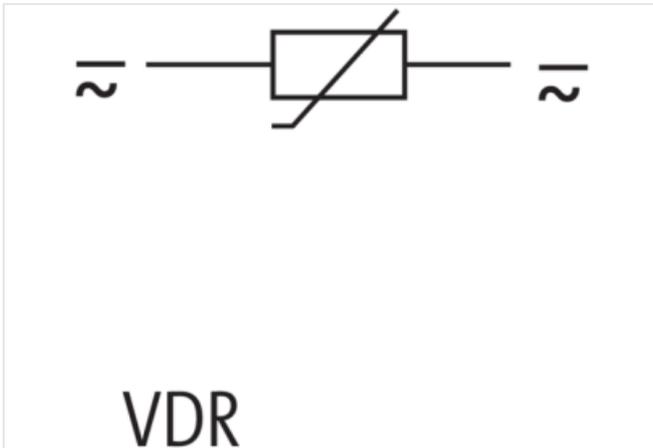
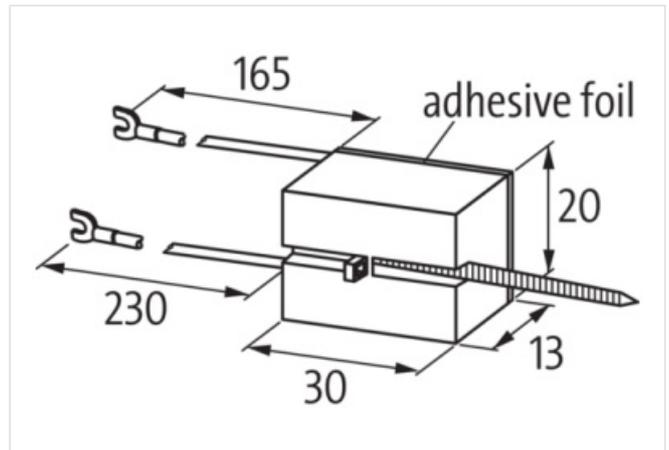
Country of origin: CZ

Model designation: VG-A / 24

24 V DC

VDR

For other configurations and voltages, please inquire.

**Link to Product****Illustration**

Product may differ from Image

**Header**

Material short text

VG-A / 24

**Commercial data**

URL Webshop

<https://shop.murrelektronik.com/26180>

GTIN	4048879018166
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879018166
Packaging unit	1

**Electrical data**

Damping factor	1.5x UN
Holding power max.	50 W

**Electrical data | Input**

Input voltage AC min.	0 V
Input voltage AC max.	30 V
Input voltage DC min.	0 V
Input voltage DC max.	30 V

**Installation | Connection**

Connection information	self-securing cable forks
------------------------	---------------------------

**Device protection | Media**

Flame resistance	flame retardant
------------------	-----------------

**Mechanical data | Material data**

Material housing	Plastic
Combustibility class housing (UL94)	V-0

**Mechanical data | Mounting data**

Height	30 mm
Width	20 mm
Depth	13 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	70 °C