

TELEMECANIQUE CONTACTOR SUPPRESSOR

Varistor, 48VAC/DC

Art.No.: 26185

Weight: 0.003 kg

Country of origin: CZ

Model designation: PZV 48

24 V AC/DC



48 V AC/DC

VDR

For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

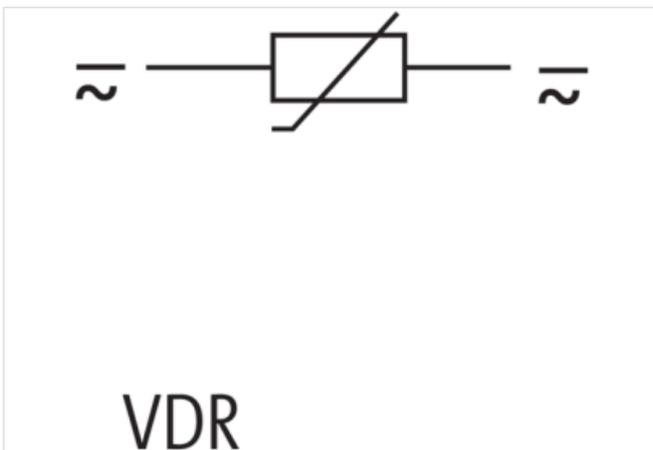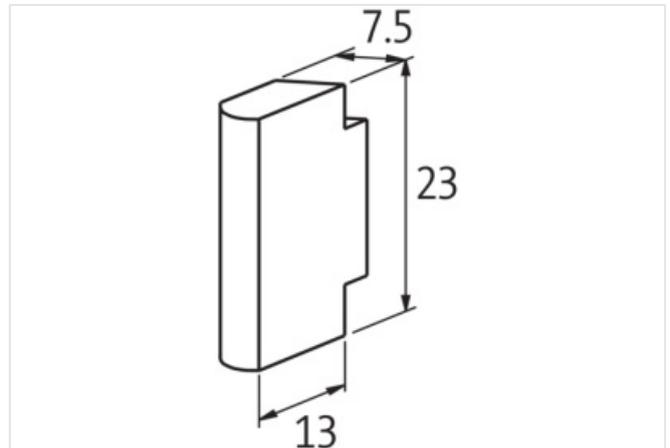

Product may differ from Image



Header

Material short text

PZV 48

Commercial data

URL Webshop	https://shop.murrelektronik.com/26185
GTIN	4048879018111
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879018111
Packaging unit	1

Electrical data

Damping factor	1.5x UN
----------------	---------

Electrical data | Input

Input voltage AC min.	24 V
Input voltage AC max.	53 V
Input voltage DC min.	24 V
Input voltage DC max.	53 V

Installation | Connection

Connection information	Plug contact
------------------------	--------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0

Mechanical data | Mounting data

Height	13 mm
Width	23 mm
Depth	7,5 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C