

ABB CONTACTOR SUPPRESSOR

Diode, 0...240VDC

Art.No.: 26440

Weight: 0.010 kg

Country of origin: CZ

Model designation: DLG ABB A9-16/24-240VDC



24...240 V DC

Diode

For other configurations and voltages, please inquire.

[Link to Product](#)

Illustration

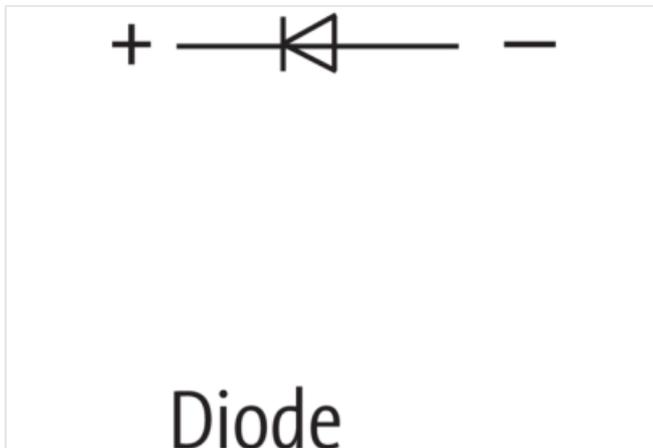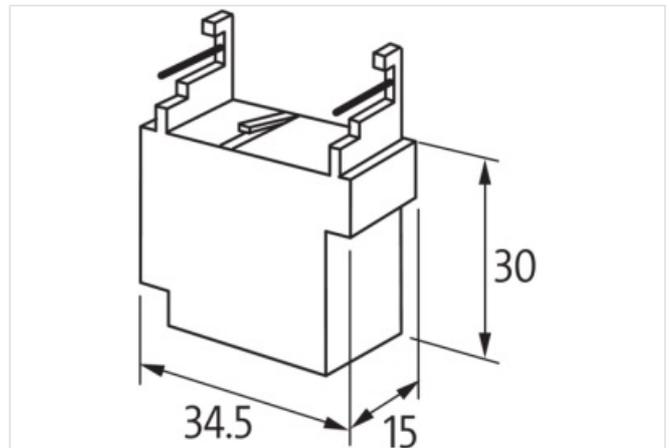

Product may differ from Image



Header

Material short text

DLG ABB A9-16/24-240VDC

Commercial data

URL Webshop

<https://shop.murrelektronik.com/26440>

GTIN	4048879017756
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879017756
Packaging unit	1

Electrical data

Damping factor	1.5x UN
----------------	---------

Electrical data | Input

Input voltage DC min.	24 V
Input voltage DC max.	240 V

Installation | Connection

Connection information	Plug contact
------------------------	--------------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	Plastic
Combustibility class housing (UL94)	V-0

Mechanical data | Mounting data

Height	40 mm
Width	34,5 mm
Depth	15 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C