

SIEMENS CONTACTOR SUPPRESSOR

Diode, 0...240VDC

Art.No.: 26520

Weight: 0.010 kg

Country of origin: CZ

Model designation: LG 24 VDC



24 V AC/DC

Diode/Z-Diode

For other configurations and voltages, please inquire.

Link to Product

Illustration

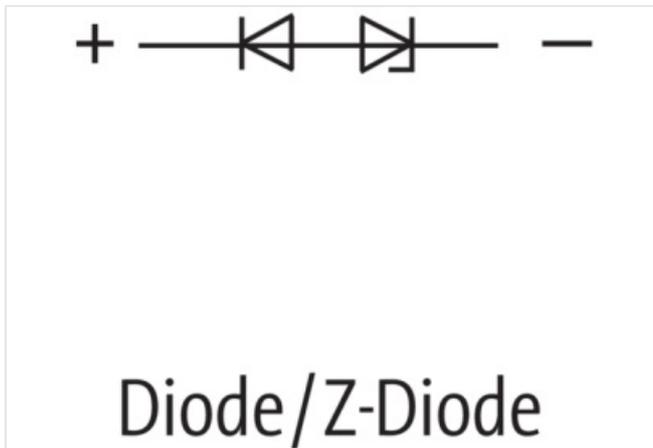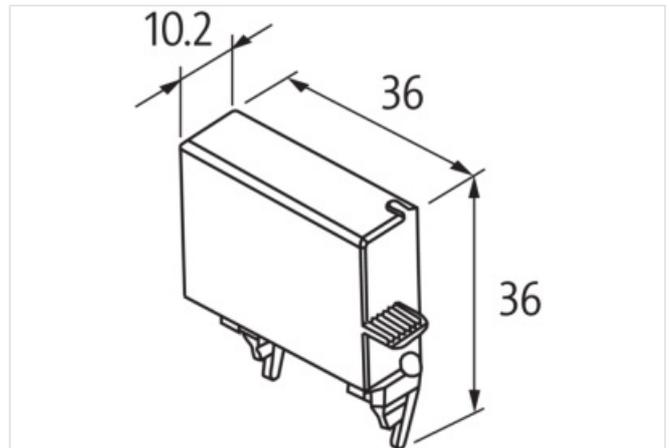

Product may differ from Image



Header

Material short text

LG 24 VDC

Commercial data

URL Webshop

<https://shop.murrelektronik.com/26520>

| | |
|-----------------------|---------------|
| GTIN | 4048879017558 |
| ECLASS-6.0 | 27371013 |
| ECLASS-6.1 | 27371013 |
| ECLASS-7.0 | 27371013 |
| ECLASS-7.1 | 27371013 |
| ECLASS-8.0 | 27371013 |
| ECLASS-8.1 | 27371013 |
| ECLASS-9.0 | 27371013 |
| ECLASS-9.1 | 27371013 |
| ECLASS-10.0.1 | 27371013 |
| ECLASS-10.1 | 27371013 |
| ECLASS-11.0 | 27371013 |
| ECLASS-11.1 | 27371013 |
| ECLASS-12.0 | 27371013 |
| ECLASS-13.0 | 27371013 |
| ECLASS-14.0 | 27371013 |
| ETIM-5.0 | EC002498 |
| ETIM-6.0 | EC002498 |
| ETIM-7.0 | EC002498 |
| ETIM-8.0 | EC002498 |
| customs tariff number | 85363010 |
| EAN | 4048879017558 |
| Packaging unit | 1 |

Electrical data | Input

| | |
|-----------------------|------|
| Input voltage DC min. | 0 V |
| Input voltage DC max. | 30 V |

Mechanical data | Mounting data

| | |
|--------|---------|
| Height | 36 mm |
| Width | 36 mm |
| Depth | 10,2 mm |

Environmental characteristics | Climatic

| | |
|----------------------------|--------|
| Operating temperature min. | -20 °C |
| Operating temperature max. | 70 °C |