

SIEMENS CONTACTOR SUPPRESSOR

Varistor, 24VAC/DC

Art.No.: 26524

Weight: 0.024 kg

Country of origin: CZ

Model designation: VG 24/48 V



24 V AC/DC

VDR

For other configurations and voltages, please inquire.

Link to Product

Illustration

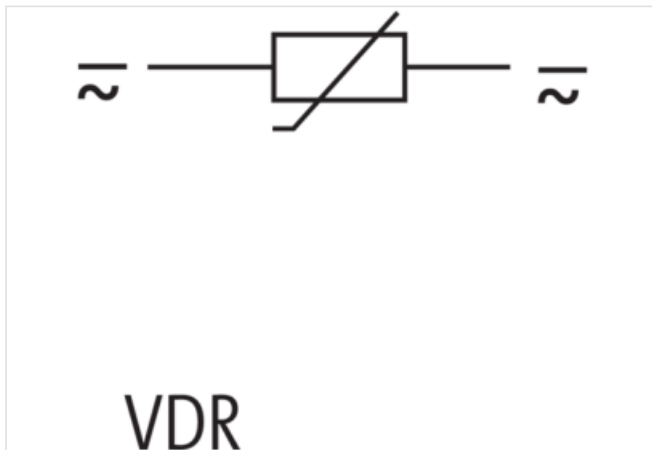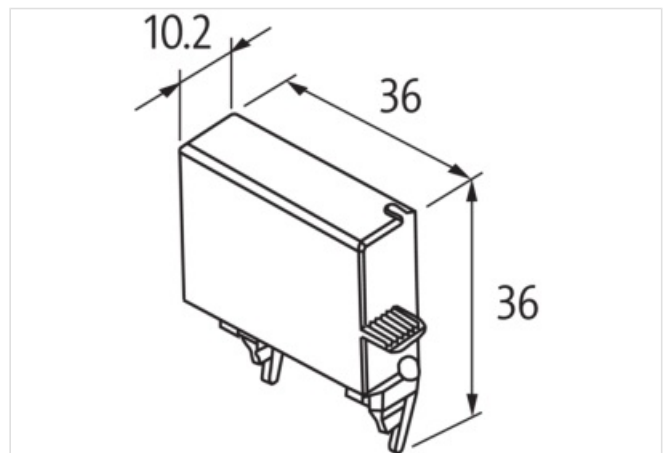

Product may differ from Image



Header

Material short text VG 24/48 V

Commercial data

URL Webshop <https://shop.murrelektronik.com/26524>

GTIN	4048879017534
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879017534
Packaging unit	1

Electrical data | Input

Input voltage AC min.	24 V
Input voltage AC max.	70 V
Input voltage DC min.	24 V
Input voltage DC max.	70 V

Mechanical data | Mounting data

Height	36 mm
Width	36 mm
Depth	10,2 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	70 °C