

## SIEMENS CONTACTOR SUPPRESSOR

Diode, 0...240VDC

Art.No.: 26528

Weight: 0.010 kg

Country of origin: CZ

Model designation: LG 24 VDC

24 V DC



Diode/Z-Diode

Mounts on the underside of the contactor

For other configurations and voltages, please inquire.

### [Link to Product](#)

#### Illustration

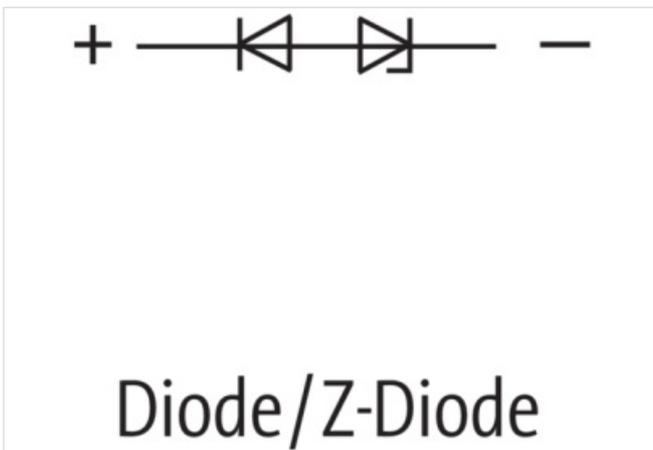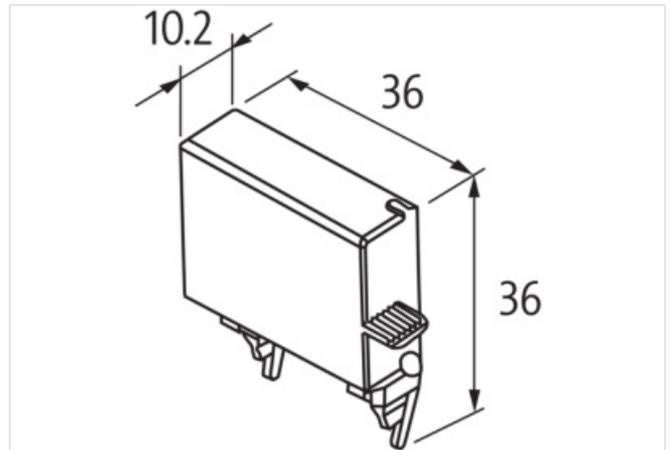

Product may differ from Image



#### Header

Material short text

LG 24 VDC

#### Commercial data

URL Webshop	<a href="https://shop.murrelektronik.com/26528">https://shop.murrelektronik.com/26528</a>
GTIN	4048879017503
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC002498
ETIM-6.0	EC002498
ETIM-7.0	EC002498
ETIM-8.0	EC002498
customs tariff number	85363010
EAN	4048879017503
Packaging unit	1

**Electrical data**

Damping factor	1.5x UN
----------------	---------

**Electrical data | Input**

Input voltage DC min.	0 V
Input voltage DC max.	30 V

**Installation | Connection**

Connection information	Plug contact
------------------------	--------------

**Device protection | Media**

Flame resistance	flame retardant
------------------	-----------------

**Mechanical data | Material data**

Material housing	Plastic
Combustibility class housing (UL94)	V-0

**Mechanical data | Mounting data**

Height	36 mm
Width	36 mm
Depth	10,2 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	70 °C