

MVP12, 4XM12, 4POLE, PLUG. CAP SCT.

Plug. cap, field-wireable via screw terminals

Art.No.: 27776

Weight: 0.098 kg

Country of origin: DE

Model designation: MVQ4-V

4-way, 4-pole


Screw plug-in terminals

Potential separation as option


with LED for digital PNP-signals 24 V DC

Plastic housings with good resistance against chemicals and oils.


The resistance to aggressive media should be individually tested for your application. Further details on request.


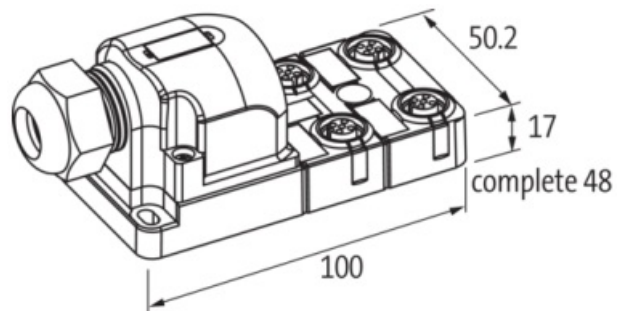
[Link to Product](#)
Illustration


M12 Females 4-pole

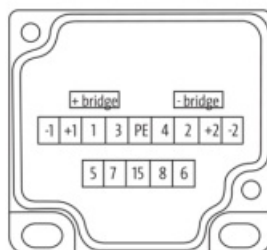

for 2 signals per port

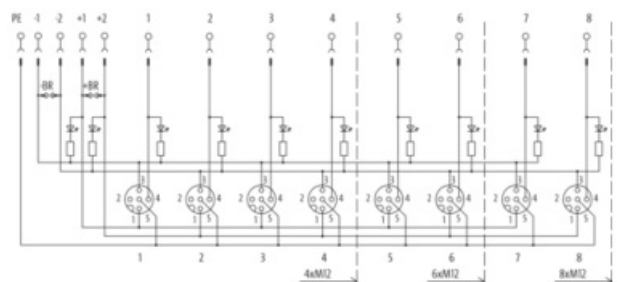

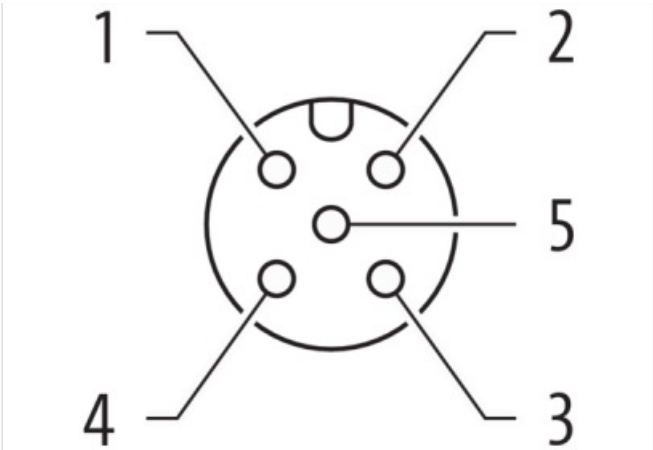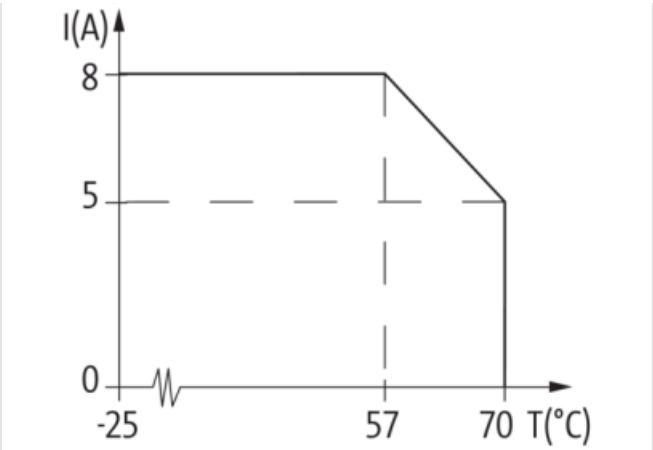

Product may differ from Image



Header	
Material short text	MVQ4-V
Commercial data	
URL Webshop	https://shop.murrelektronik.com/27776
GTIN	4048879063272
ECLASS-6.0	27279219
ECLASS-6.1	27279219
ECLASS-7.0	27279219
ECLASS-7.1	27279219
ECLASS-8.0	27279219
ECLASS-8.1	27279219
ECLASS-9.0	27440111
ECLASS-10.0.1	27440111
ECLASS-10.1	27440111
ECLASS-11.0	27440111
ECLASS-11.1	27440111
ECLASS-12.0	27440111
ECLASS-13.0	27440111
ECLASS-14.0	27440111
ETIM-5.0	EC002585
ETIM-6.0	EC002585
ETIM-7.0	EC002585
ETIM-8.0	EC002585
customs tariff number	85366990
EAN	4048879063272
Packaging unit	1
Installation	
Connection cross section max.	1,5 mm²
AWG number max.	16
Installation Connection	
Connection	Screw plug-in terminals
Device protection Media	

Flame resistance flame retardant

Mechanical data | Material data

Material housing Plastic

Mechanical data | Mounting data

Height 100 mm

Width 50,2 mm

Depth 17 mm

Environmental characteristics | Climatic

Operating temperature min. -20 °C

Operating temperature max. 80 °C

Connection type 2

Family construction form Cap

No. of poles 21

Family construction form M12

No. of poles 5

Coding A

Gender female

Color contact carrier black

PIN 1 24 V DC

PIN 2 S 2

PIN 3 0 V

PIN 4 S 1

PIN 5 FE