

MVP12, 8XM12, 4POLE, PLUG. CAP SCT.




Plug. cap, field-wireable via screw terminals



Art.No.: 27778
 Weight: 0.130 kg
 Country of origin: DE
 Model designation: MVQ8-V

8-way, 4-pole
 Screw plug-in terminals
 Potential separation as option
 with LED for digital PNP-signals 24 V DC
 Plastic housings with good resistance against chemicals and oils.
 The resistance to aggressive media should be individually tested for your application. Further details on request.

[Link to Product](#)

Illustration

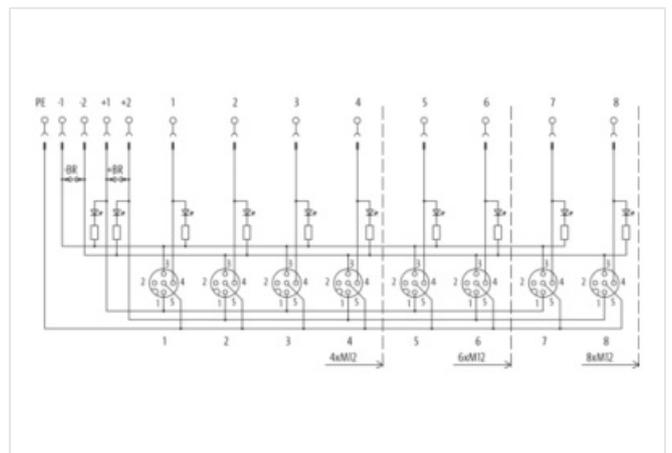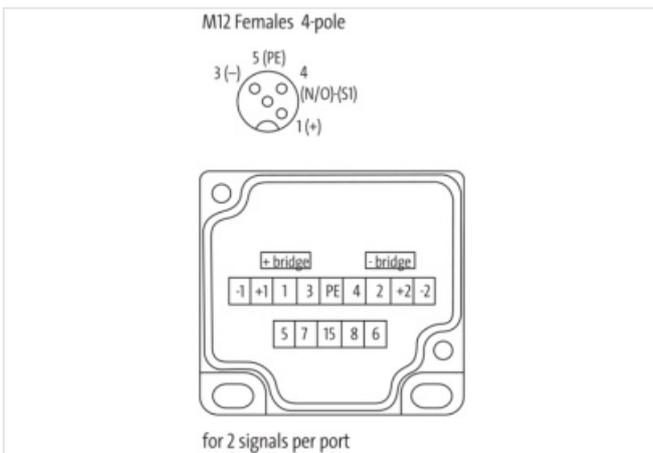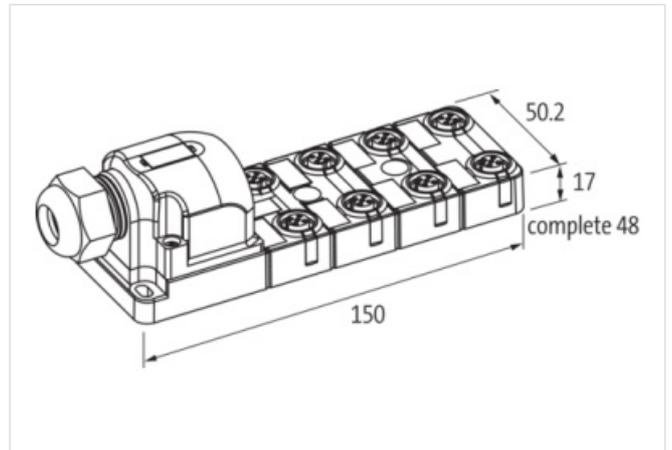

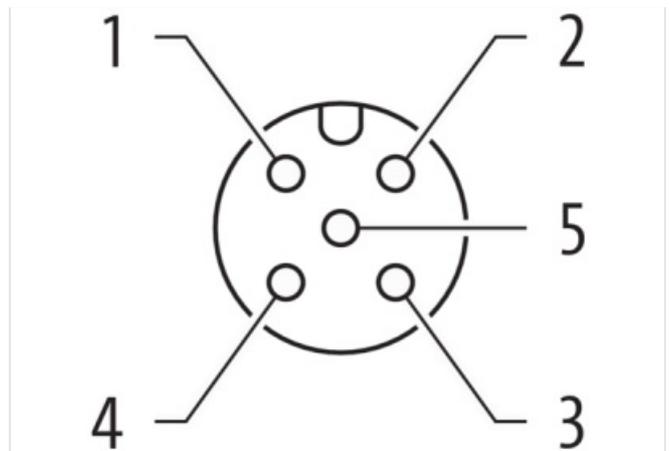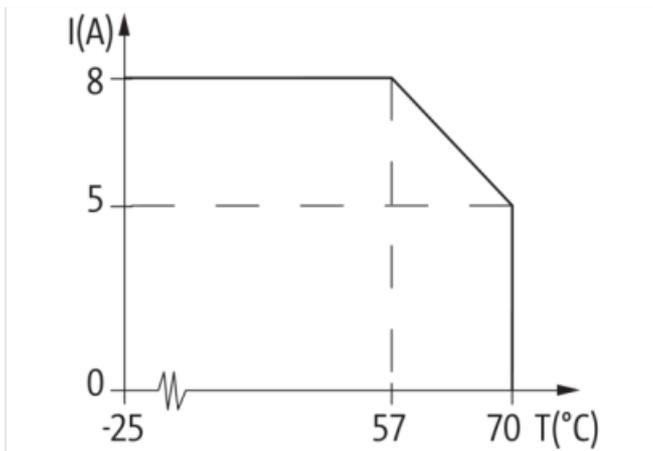

Product may differ from Image

**Header**

Material short text MVQ8-V

Commercial dataURL Webshop <https://shop.murrelektronik.com/27778>

GTIN 4048879063258

ECLASS-6.0 27279219

ECLASS-6.1 27279219

ECLASS-7.0 27279219

ECLASS-7.1 27279219

ECLASS-8.0 27279219

ECLASS-8.1 27279219

ECLASS-9.0 27440111

ECLASS-10.0.1 27440111

ECLASS-10.1 27440111

ECLASS-11.0 27440111

ECLASS-11.1 27440111

ECLASS-12.0 27440111

ECLASS-13.0 27440111

ECLASS-14.0 27440111

ETIM-5.0 EC002585

ETIM-6.0 EC002585

ETIM-7.0 EC002585

ETIM-8.0 EC002585

customs tariff number 85366990

EAN 4048879063258

Packaging unit 1

InstallationConnection cross section max. 1,5 mm²

AWG number max. 16

Installation | Connection

Connection Screw plug-in terminals

Device protection | Media

