

MIRO 6.2 PLUGGABLE PLUG IN MODULE OUTPUT RELAY

IN: 12 VAC/DC - OUT: 250 VAC/DC / 6 A

Art.No.: 3000-16023-2100005

Weight: 0.006 kg

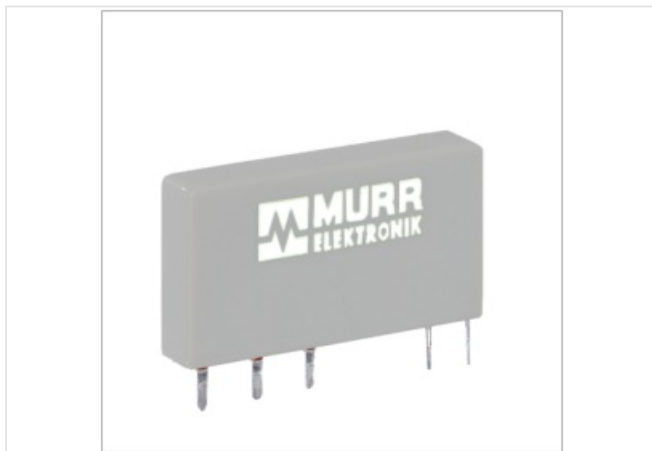
Country of origin: CZ

Model designation: Ausgrel. 12V/230V 6A (Steckmodul)

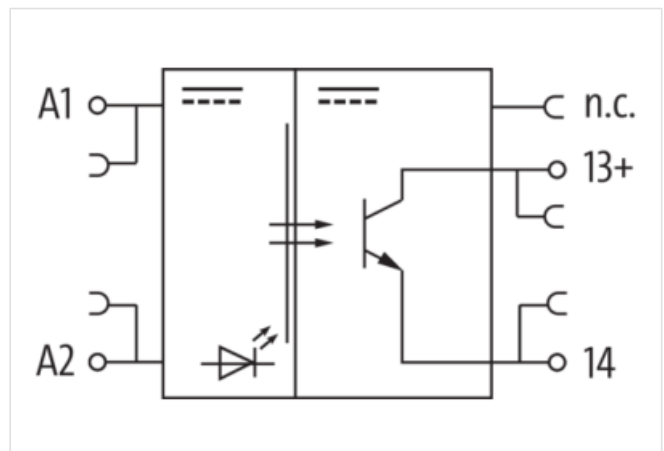
Output relay

1 relay; 1 NO contact

12 V AC/DC

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text Ausgrel. 12V/230V 6A (Steckmodul)

Commercial data

URL Webshop	https://shop.murrelektronik.com/3000-16023-2100005
GTIN	4048879021388
ECLASS-6.0	27371601
ECLASS-6.1	27371601
ECLASS-7.0	27371601
ECLASS-7.1	27371601
ECLASS-8.0	27371601
ECLASS-8.1	27371601
ECLASS-9.0	27371601
ECLASS-9.1	27371601
ECLASS-10.0.1	27371601
ECLASS-10.1	27371601
ECLASS-11.0	27371601
ECLASS-11.1	27371601
ECLASS-12.0	27371601
ECLASS-13.0	27371601

ECLASS-14.0	27371601
ETIM-5.0	EC001437
ETIM-6.0	EC001437
ETIM-7.0	EC001437
ETIM-8.0	EC001437
customs tariff number	85364900
EAN	4048879021388
Packaging unit	1
Electrical data Output	
Switching voltage AC max.	250 V
Switching voltage DC max.	30 V
Switching current max.	6 A
Switching current DC	10 mA
Power rating AC max.	1.500 VA
Power rating DC max.	120 W
Device protection Electrical	
Rated insulation voltage	300 V
Mechanical data	
Response time max.	8 ms
Drop-out time max.	4 ms
Mechanical data Material data	
Material contact	Ag Sn O2
Mechanical data Mounting data	
Mounting method	inserted
Environmental characteristics Climatic	
Operating temperature min.	-40 °C
Operating temperature max.	60 °C
Ambient temperature (storage, transport)	-40 °C