

VALVE PLUG SUPPRESSOR FORM A - 18MM

With LED, 48VAC/DC/50VA/W

Art.No.: 3124017

Weight: 0.020 kg

Country of origin: CZ

Model designation: VBS-LEDY 48 U



48 V AC/DC

LED

Remove plug gasket when fitting adapter. Other LED colors on request.

Link to Product

Illustration

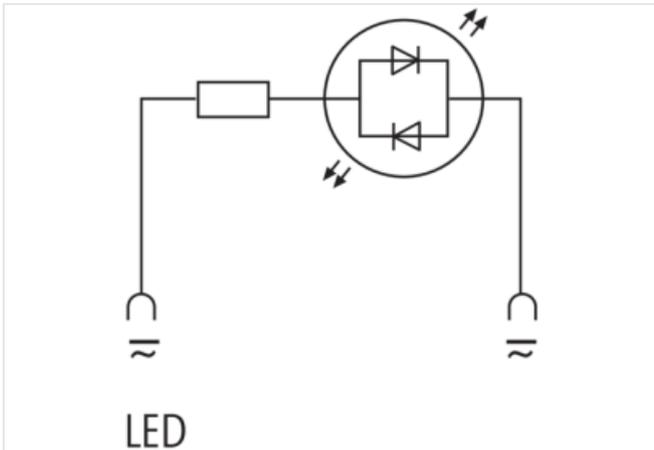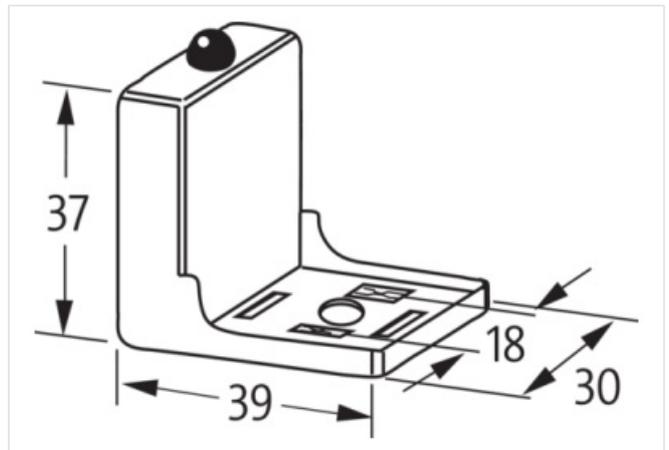

Product may differ from Image



Header

Material short text

VBS-LEDY 48 U

Commercial data

URL Webshop

<https://shop.murrelektronik.com/3124017>

GTIN	4048879012287
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879012287
Packaging unit	1

Electrical data

Holding power max.	50 W
--------------------	------

Electrical data | Input

Input voltage AC min.	30 V
Input voltage AC max.	53 V
Input voltage DC min.	30 V
Input voltage DC max.	53 V

Diagnostics

Status indication LED	yellow
-----------------------	--------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	PA
Color housing	black
Material contact	Bronze
Coating contact	silver-plated

Mechanical data | Mounting data

Height	37 mm
Width	39 mm
Depth	30 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Housing temperature max. (EN 61347-2-13)	130 °C