

VALVE PLUG SUPPRESSOR FORM A - 18MM

Diode and LED, 24VDC/50VA/W

Art.No.: 3124021

Weight: 0.013 kg

Country of origin: CZ

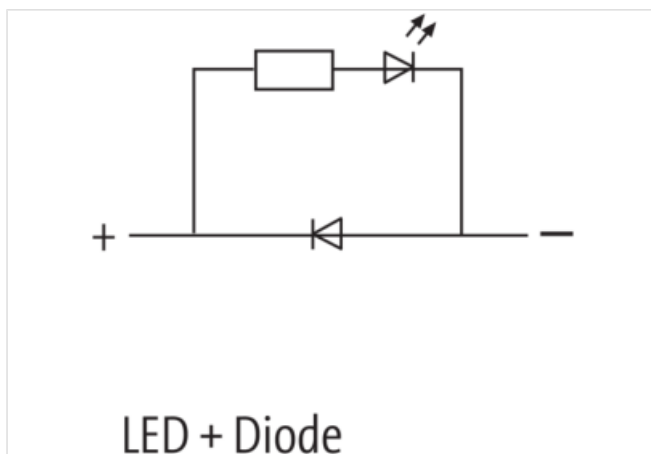
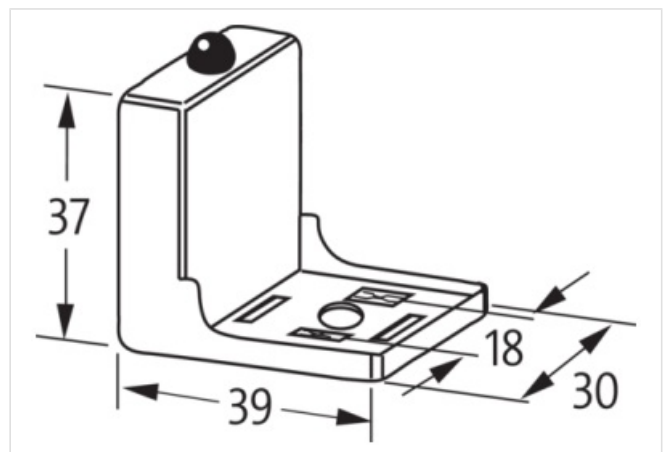
Model designation: VBS-LEDY+DIODE 24 V

24 V DC

Diode + LED

Remove plug gasket when fitting adapter. Other LED colors on request.

Polarity dependent

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

VBS-LEDY+DIODE 24 V

Commercial data

URL Webshop	https://shop.murrelektronik.com/3124021
GTIN	4048879012263
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879012263
Packaging unit	1

Electrical data

Drop-out delay time max.	200 ms
Holding power max.	50 W

Electrical data | Supply

Cut-off peak voltage max.	1 V
---------------------------	-----

Electrical data | Input

Input voltage DC min.	12 V
Input voltage DC max.	30 V

Diagnostics

Status indication LED	yellow
-----------------------	--------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	PA
Color housing	black
Material contact	Bronze
Coating contact	silver-plated

Mechanical data | Mounting data

Height	37 mm
Width	39 mm
Depth	30 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Housing temperature max. (EN 61347-2-13)	130 °C