

VALVE PLUG SUPPRESSOR FORM A - 18MM

Varistor and LED, 110VAC/DC/100VA/W

Art.No.: 3124046

Weight: 0.026 kg

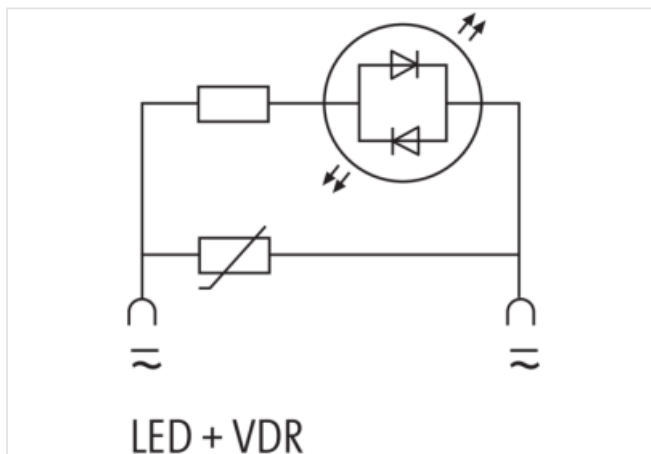
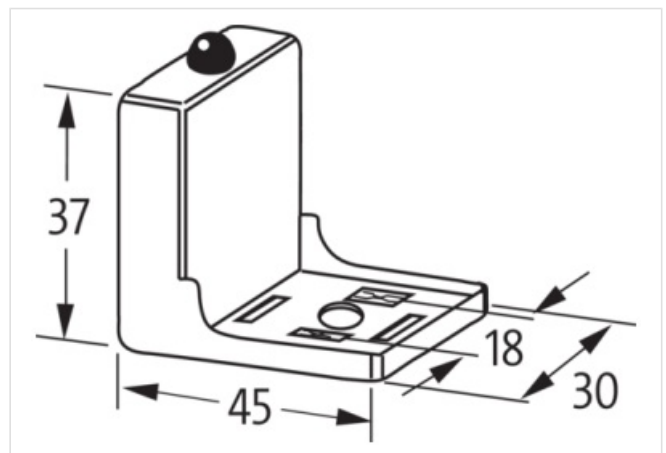
Country of origin: CZ

Model designation: VBS-LEDY+VDR 110 U

110 V AC/DC

VDR + LED

Remove plug gasket when fitting adapter. Other LED colors on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

VBS-LEDY+VDR 110 U

Commercial data

URL Webshop

<https://shop.murrelektronik.com/3124046>

GTIN	4048879012225
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879012225
Packaging unit	1
customs tariff number	85363010
EAN	4048879012225
Packaging unit	1
Electrical data	
Drop-out delay time max.	10 ms
Holding power max.	100 W
Electrical data Supply	
Cut-off peak voltage max.	235 V
Electrical data Input	
Input voltage AC min.	48 V
Input voltage AC max.	130 V
Input voltage DC min.	48 V
Input voltage DC max.	130 V
Diagnostics	
Status indication LED	yellow
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	PA
Color housing	black
Material contact	Bronze
Coating contact	silver-plated
Mechanical data Mounting data	
Height	37 mm
Width	45 mm
Depth	30 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C

Operating temperature max.	60 °C
Housing temperature max. (EN 61347-2-13)	130 °C