

VALVE PLUG SUPPRESSOR FORM A - 18MM

Varistor and LED, 24VAC/DC/50VA/W

Art.No.: 3124048

Weight: 0.018 kg

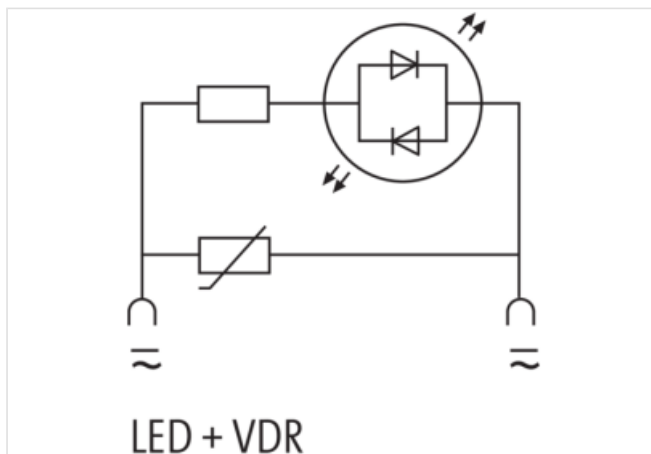
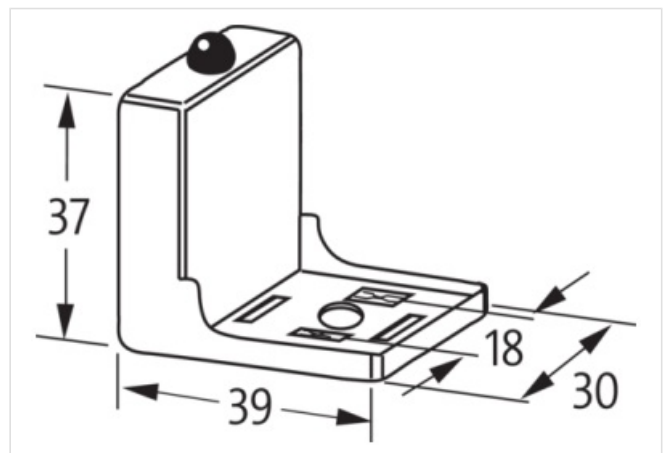
Country of origin: CZ

Model designation: VBS-LEDY+VDR 24 U

24 V AC/DC

VDR + LED

Remove plug gasket when fitting adapter. Other LED colors on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

VBS-LEDY+VDR 24 U

Commercial data

URL Webshop

<https://shop.murrelektronik.com/3124048>

GTIN	4048879012218
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879012218
Packaging unit	1
customs tariff number	85363010
EAN	4048879012218
Packaging unit	1
Electrical data	
Drop-out delay time min.	15 ms
Holding power max.	50 W
Electrical data Supply	
Cut-off peak voltage max.	45 V
Electrical data Input	
Input voltage AC min.	12 V
Input voltage AC max.	25 V
Input voltage DC min.	12 V
Input voltage DC max.	25 V
Diagnostics	
Status indication LED	yellow
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	PA
Color housing	black
Material contact	Bronze
Coating contact	silver-plated
Mechanical data Mounting data	
Height	37 mm
Width	39 mm
Depth	30 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C

Operating temperature max.	60 °C
Housing temperature max. (EN 61347-2-13)	130 °C