

**VALVE PLUG SUPPRESSOR FORM A - 18MM**

Varistor and LED, 230VAC/DC/100VA/W

Art.No.: 3124049

Weight: 0.025 kg

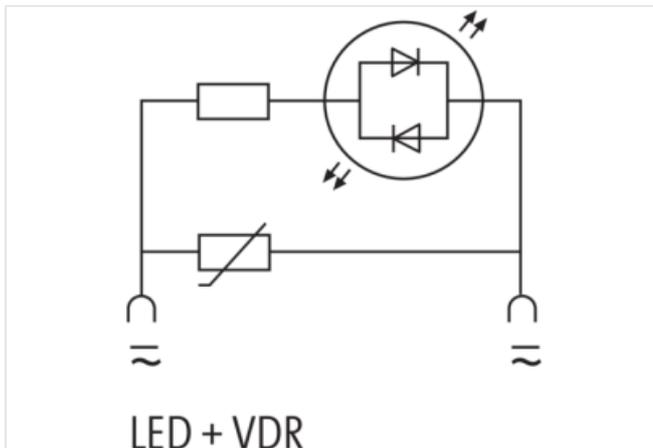
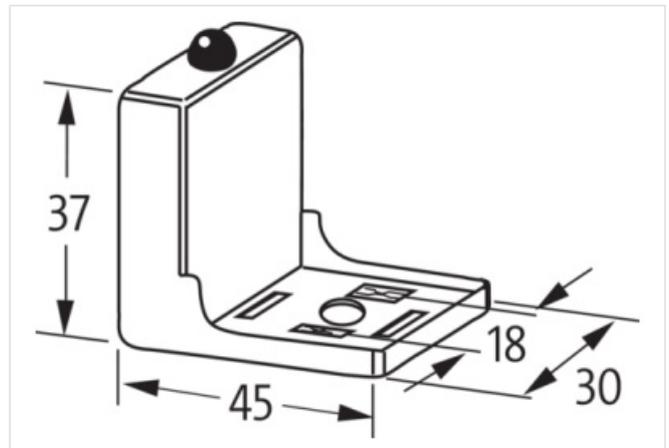
Country of origin: CZ

Model designation: VBS-LEDY+VDR 230 U

230 V AC/DC

VDR + LED

Remove plug gasket when fitting adapter. Other LED colors on request.

**[Link to Product](#)****Illustration**

Product may differ from Image

**Header**

Material short text

VBS-LEDY+VDR 230 U

**Commercial data**

URL Webshop

<https://shop.murrelektronik.com/3124049>

GTIN	4048879012201
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879012201
Packaging unit	1

**Electrical data**

Drop-out delay time min.	15 ms
Holding power max.	100 W

**Electrical data | Supply**

Cut-off peak voltage max.	360 V
---------------------------	-------

**Electrical data | Input**

Input voltage AC min.	110 V
Input voltage AC max.	250 V
Input voltage DC min.	110 V
Input voltage DC max.	250 V

**Diagnostics**

Status indication LED	yellow
-----------------------	--------

**Device protection | Media**

Flame resistance	flame retardant
------------------	-----------------

**Mechanical data | Material data**

Material housing	PA
Color housing	black
Material contact	Bronze
Coating contact	silver-plated

**Mechanical data | Mounting data**

Height	37 mm
Width	45 mm
Depth	30 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Housing temperature max. (EN 61347-2-13)	130 °C