

VALVE PLUG SUPPRESSOR FORM A - 18MM

Varistor and LED, 48VAC/DC/100VA/W

Art.No.: 3124052

Weight: 0.013 kg

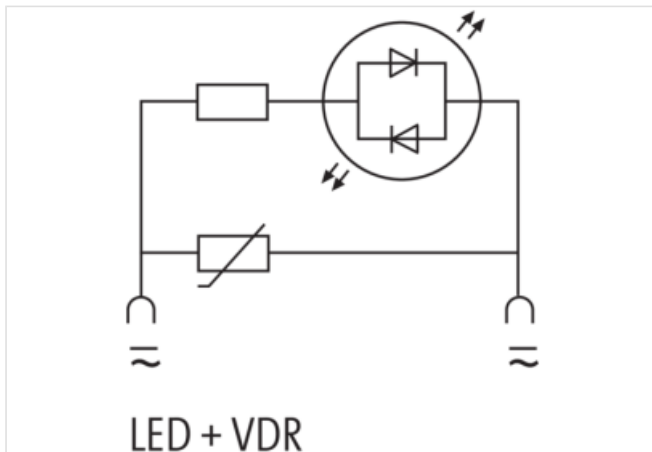
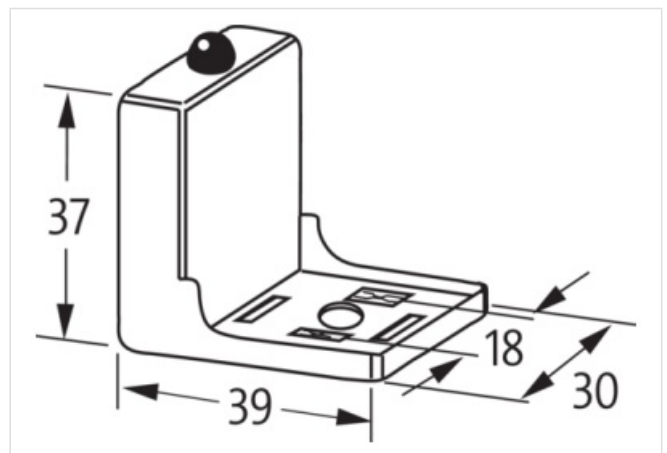
Country of origin: CZ

Model designation: VBS-LEDY+VDR 48 U

48 V AC/DC

VDR + LED

Remove plug gasket when fitting adapter. Other LED colors on request.

Link to Product**Illustration**

Product may differ from Image

**Header**

Material short text VBS-LEDY+VDR 48 U

Commercial dataURL Webshop <https://shop.murrelektronik.com/3124052>

GTIN	4048879012195
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879012195
Packaging unit	1
customs tariff number	85363010
EAN	4048879012195
Packaging unit	1
Electrical data	
Drop-out delay time max.	10 ms
Holding power max.	100 W
Electrical data Supply	
Cut-off peak voltage max.	75 V
Electrical data Input	
Input voltage AC min.	24 V
Input voltage AC max.	53 V
Input voltage DC min.	24 V
Input voltage DC max.	53 V
Diagnostics	
Status indication LED	yellow
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	PA
Color housing	black
Material contact	Bronze
Coating contact	silver-plated
Mechanical data Mounting data	
Height	37 mm
Width	39 mm
Depth	30 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C

Operating temperature max.	60 °C
Housing temperature max. (EN 61347-2-13)	130 °C