

VALVE PLUG SUPPRESSOR FORM BI - 11MM 90°

Varistor and LED, 24VAC/DC/50VA/W

Art.No.: 3124148

Weight: 0.012 kg

Country of origin: CZ

Model designation: PBS-LEDY+VDR 24 U

24 V AC/DC

VDR + LED

Remove plug gasket when fitting adapter. Other LED colors on request.


Note PIN arrangement (PE at cable outlet of connector). 180° turned version on request.

Link to Product

Illustration



Product may differ from Image

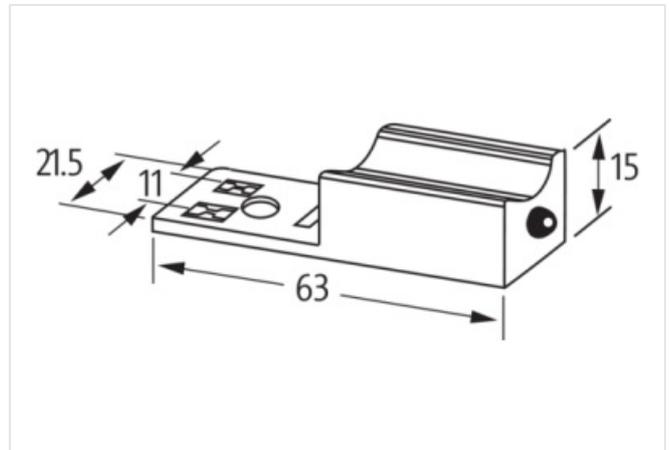

Header

Material short text PBS-LEDY+VDR 24 U

Commercial data

URL Webshop	https://shop.murrelektronik.com/3124148
GTIN	4048879012041
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013

ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879012041
Packaging unit	1

Electrical data

Drop-out delay time min.	15 ms
Holding power max.	50 W

Electrical data | Supply

Cut-off peak voltage max.	45 V
---------------------------	------

Electrical data | Input

Input voltage AC min.	0 V
Input voltage AC max.	32 V
Input voltage DC min.	0 V
Input voltage DC max.	32 V

Diagnostics

Status indication LED	yellow
-----------------------	--------

Device protection | Media

Flame resistance	flame retardant
------------------	-----------------

Mechanical data | Material data

Material housing	PA
Color housing	black
Material contact	Bronze
Coating contact	silver-plated

Mechanical data | Mounting data

Height	15 mm
Width	63 mm
Depth	21,5 mm

Environmental characteristics | Climatic

Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Housing temperature max. (EN 61347-2-13)	130 °C