

VALVE PLUG SUPPRESSOR FORM BI - 11MM

Diode and LED, 24VDC/50VA/W

Art.No.: 3124221

Weight: 0.012 kg

Country of origin: CZ

Model designation: LBS-LEDY+DIODE 24 V

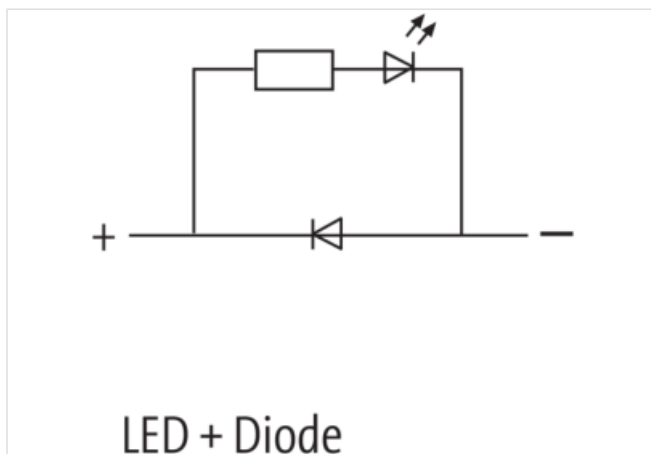
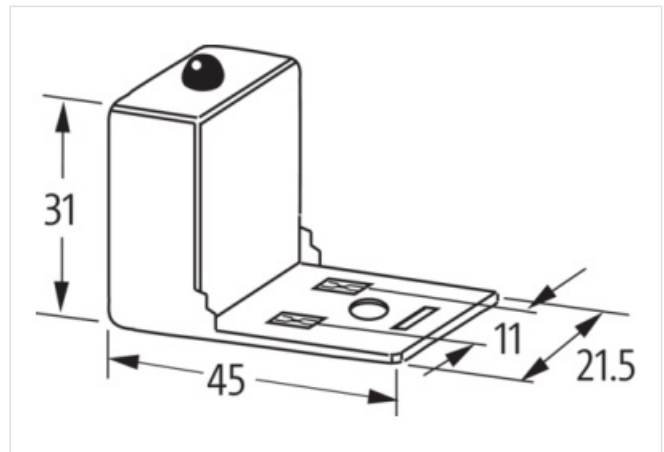
24 V DC

Diode + LED

Remove plug gasket when fitting adapter. Other LED colors on request.

Polarity dependent

Note PIN arrangement (PE at cable outlet of connector). 180° turned version on request.

[Link to Product](#)**Illustration**

Product may differ from Image

**Header**

Material short text

LBS-LEDY+DIODE 24 V

Commercial data

URL Webshop	https://shop.murrelektronik.com/3124221
GTIN	4048879011945
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879011945
Packaging unit	1
Electrical data	
Drop-out delay time max.	200 ms
Holding power max.	50 W
Electrical data Supply	
Cut-off peak voltage max.	1 V
Electrical data Input	
Input voltage DC min.	12 V
Input voltage DC max.	30 V
Diagnostics	
Status indication LED	yellow
Device protection Media	
Flame resistance	flame retardant
Mechanical data Material data	
Material housing	PA
Color housing	black
Material contact	Bronze
Coating contact	silver-plated
Mechanical data Mounting data	
Height	31 mm
Width	45 mm
Depth	21,5 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C
Housing temperature max. (EN 61347-2-13)	130 °C