

VALVE PLUG SUPPRESSOR FORM A - 18MM

Zener diode and LED, 24VDC/30VA/W

Art.No.: 3124680

Weight: 0.042 kg

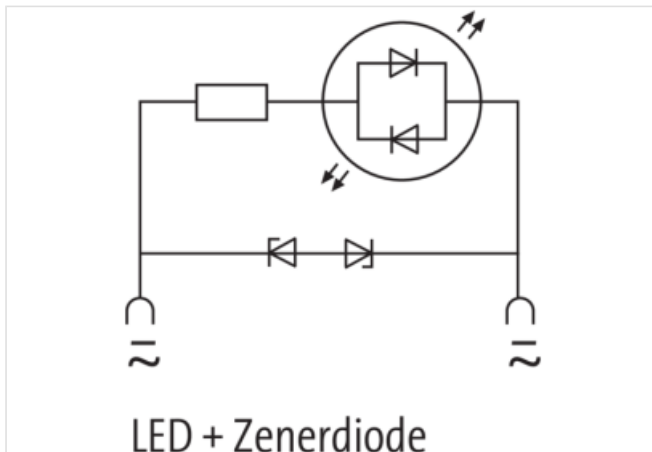
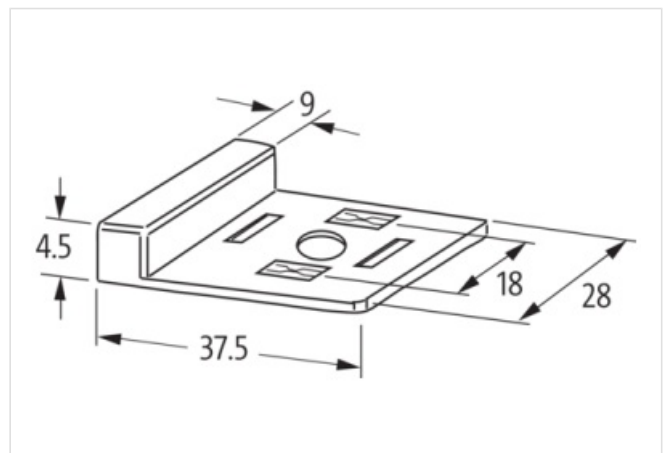
Country of origin: CZ

Model designation: MLA LEDY Z Diode 24V

24 V AC/DC

Z Diode + LED (yellow)

Remove plug gasket when fitting adapter. Other LED colors on request.

Link to Product**Illustration**

Product may differ from Image

**Header**

Material short text

MLA LEDY Z Diode 24V

Commercial data

URL Webshop

<https://shop.murrelektronik.com/3124680>

GTIN	4048879011624
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879011624
Packaging unit	1
Electrical data	
Drop-out delay time max.	200 ms
Holding power max.	30 W
Electrical data Supply	
Cut-off peak voltage max.	1 V
Electrical data Input	
Input voltage AC min.	20 V
Input voltage AC max.	32 V
Input voltage DC min.	20 V
Input voltage DC max.	32 V
Diagnostics	
Status indication LED	yellow
Installation	
Type of contact	A
Contact distance	18 mm
Mechanical data Material data	
Material housing	PUR
Material contact	Bronze
Coating contact	silver-plated
Mechanical data Mounting data	
Height	4,5 mm
Width	37,5 mm
Depth	28 mm
Environmental characteristics Climatic	
Operating temperature min.	-20 °C
Operating temperature max.	60 °C