

**VALVE PLUG SUPPRESSOR FORM A - 18MM**

Diode and LED, 24VDC/60VA/W

Art.No.: 3124681

Weight: 0.042 kg

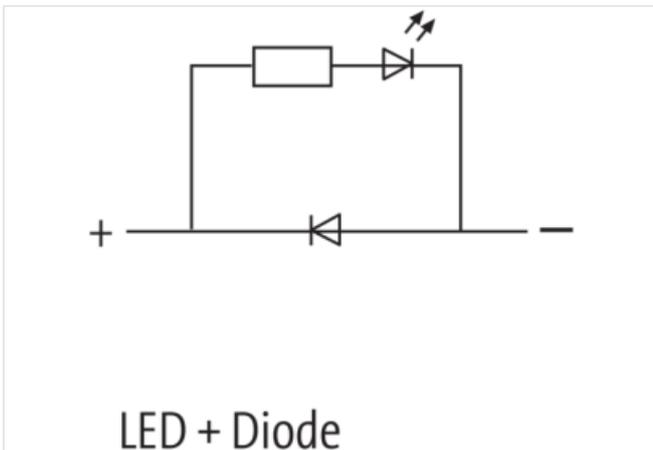
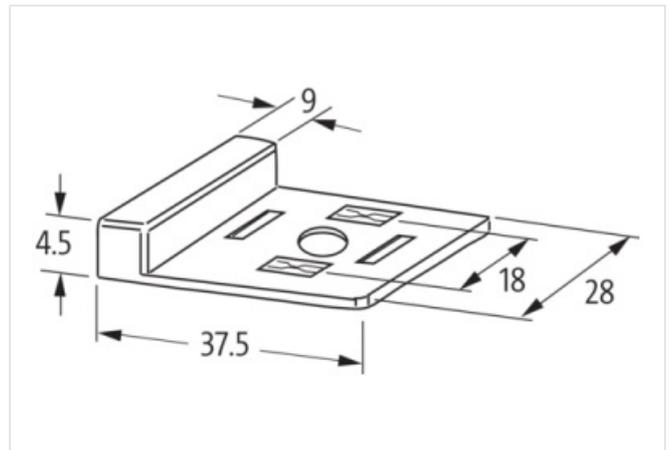
Country of origin: DE

Model designation: MLA LEDY TVS Diode 24V

24 V AC/DC

Diode + LED (yellow)

Remove plug gasket when fitting adapter. Other LED colors on request.

**Link to Product****Illustration**

Product may differ from Image

**Header**

Material short text

MLA LEDY TVS Diode 24V

**Commercial data**

URL Webshop

<https://shop.murrelektronik.com/3124681>

GTIN	4048879011617
ECLASS-6.0	27371013
ECLASS-6.1	27371013
ECLASS-7.0	27371013
ECLASS-7.1	27371013
ECLASS-8.0	27371013
ECLASS-8.1	27371013
ECLASS-9.0	27371013
ECLASS-9.1	27371013
ECLASS-10.0.1	27371013
ECLASS-10.1	27371013
ECLASS-11.0	27371013
ECLASS-11.1	27371013
ECLASS-12.0	27371013
ECLASS-13.0	27371013
ECLASS-14.0	27371013
ETIM-5.0	EC000683
ETIM-6.0	EC000683
ETIM-7.0	EC000683
ETIM-8.0	EC000683
customs tariff number	85363010
EAN	4048879011617
Packaging unit	1

**Electrical data**

Drop-out delay time max.	200 ms
Holding power max.	60 W

**Electrical data | Supply**

Cut-off peak voltage max.	1 V
---------------------------	-----

**Electrical data | Input**

Input voltage AC min.	21 V
Input voltage AC max.	28 V
Input voltage DC min.	21 V
Input voltage DC max.	28 V

**Diagnostics**

Status indication LED	green
-----------------------	-------

**Installation**

Type of contact	A
Contact distance	18 mm

**Mechanical data | Material data**

Material housing	PUR
Material contact	Bronze
Coating contact	silver-plated

**Mechanical data | Mounting data**

Height	4,5 mm
Width	37,5 mm
Depth	28 mm

**Environmental characteristics | Climatic**

Operating temperature min.	-20 °C
Operating temperature max.	60 °C